

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0639037100**
Status: **Active**
Overview: Application Tooling
Description: FineAdjust Applicator for Mini-Fit TPA2 Crimp Terminals, 0.22mm², 0.25mm², 0.35 mm² and 22-24 AWG wires

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)


General

Product Family	Application Tooling
Series	<u>207127</u>
Comments	See Tooling Specification (PDF) Above
Function	Crimp
Geographic Area	Global
Level of Automation	Automatic, Semi-Automatic
More Detailed Tech Information	applicationtooling@molex.com
Overview	<u>Application Tooling</u>
Product Name	FineAdjust, Mini-Fit TPA2
Tool Type	Applicator
UPC	889056478823
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers
Application Tooling Documents

ATS-639037100-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001, TM-638004900-001, TM-638004900CN-001, TM-638004900DE-001, TM-638004900FR-001, TM-638004900IT-001, TM-638004900JP-001, TM-638004900KR-001, TM-638004900MY-001, TM-638004900PL-001, TM-638004900RU-001, TM-638004900SK-001, TM-638004900SP-001, TM-638004900TH-001, TM-638004900TW-001, TM-638004900VN-001

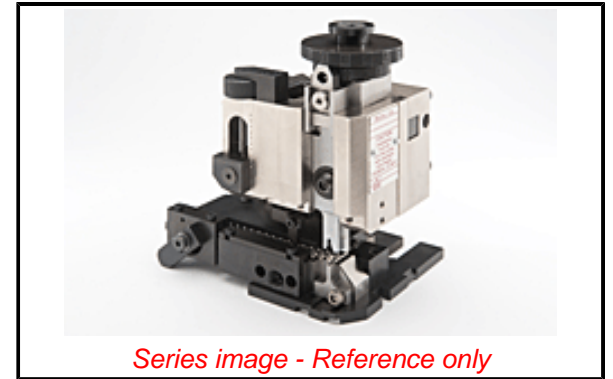

EU ELV

Not Relevant

EU RoHS

Not Relevant

REACH SVHC

Not Relevant

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Relevant

Search Parts in this Series

207127 Series

Use With

Molex TM-3000: [638017200](#) , [638017300](#) , Molex TM-4000: [638017600](#) , Molex TM-2000: [638008300](#) , [638008400](#) , and Most Industry Standard Presses or Wire Process Machines

Application Tooling

Description

FAQ

Product #

Mini-Fit TPA2/ [1727185111](#)

Sigma Female Crimp Terminal, Phosphor Bronze, Pre-Plated Tin (Sn), 22-24 AWG, 1.07-1.65mm Insulation Diameter, Reel

Mini-Fit TPA2/ [1727185121](#)

Sigma Female Crimp Terminal, Brass, Pre-Plated Tin (Sn), 22-24 AWG, 1.07-1.65mm

Insulation Diameter, Reel	
Mini-Fit TPA2/ Sigma Male Crimp Terminal, Brass, Pre-Plated Tin (Sn), 22-24 AWG, 1.07-1.65mm Insulation Diameter, Reel	<u>1727655121</u>
Mini-Fit TPA2/ Sigma Female Crimp Terminal, Copper Alloy, Post-Plated Gold (Au), 22-24 AWG, 1.07-1.65mm Insulation Diameter, Reel	<u>2029885141</u>
Mini-Fit TPA2/ Sigma Female Crimp Terminal, Copper Alloy, Post-Plated Tin (Sn), 22-24 AWG, 1.07-1.65mm Insulation Diameter, Reel	<u>2029885241</u>
Mini-Fit TPA2/ Sigma Male Crimp Terminal, Copper Alloy, Post-Plated Gold (Au), 22-24 AWG, 1.07-1.65mm Insulation Diameter, Reel	<u>2030705141</u>
Mini-Fit TPA2/ Sigma Male Crimp Terminal, Copper Alloy, Post-Plated Tin (Sn), 22-24 AWG, 1.07-1.65mm Insulation Diameter, Reel	<u>2030705241</u>

This document was generated on 10/07/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63903-7100](#)