

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0640010200](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: PremiumGrade Hand Crimp Tool for Insulkrimp Quick Disconnect Terminals, 10-22 AWG

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Application Tooling
Series	207129
Comments	ServiceGrade Hand Tool 640160037 Type RHT
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	N/A
Tool Type	Hand Crimp Tool
UPC	756054219881
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Engineering Number RHT-1991

Reference - Drawing Numbers

Application Tooling Documents
 ATS-640010200-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

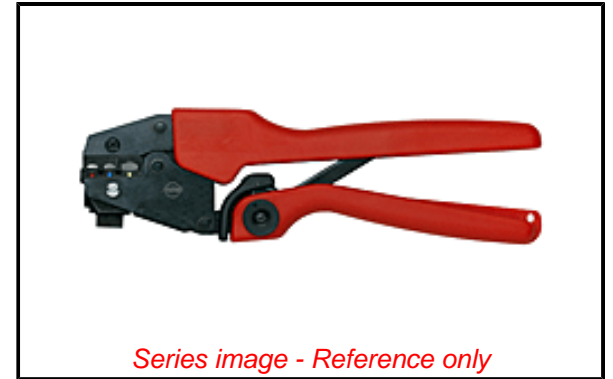

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[207129](#) Series

Use With

Loose Piece Terminals

Application Tooling Description

FAQ Product #

Avikrimp Quick Disconnect, Female, for 10-12 (5.00-3.30mm²) Wire, Box, Tab 6.35 x 0.81mm

[190020044](#)

InsulKrimp Quick Disconnect, Female, for 18-22 (0.80-0.35mm²) Wire, Box, Tab 2.79 x 0.51mm

[190170001](#)

InsulKrimp Quick Disconnect, Female, for 18-22 (0.80-0.35mm²) Wire,

[190170005](#)

Box, Tab 2.79 x
0.81mm
InsulKrimp Quick 190170007
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Box, Tab 4.75 x
0.51mm
InsulKrimp Quick 190170008
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Box, Tab 4.75 x
0.81mm
InsulKrimp Quick 190170014
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Box, Tab 6.35 x
0.81mm
InsulKrimp Quick 190170018
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Box, Tab 5.21 x
0.51mm
InsulKrimp Quick 190170023
Disconnect,
Female, for 14-16
(2.00-1.30mm²) Wire,
Box, Tab 2.79 x
0.51mm
InsulKrimp Quick 190170028
Disconnect,
Female, for 14-16
(2.00-1.30mm²) Wire,
Box, Tab 2.79 x
0.81mm
InsulKrimp Quick 190170031
Disconnect,
Female, for 14-16
(2.00-1.30mm²) Wire,
Box, Tab 4.75 x
0.51mm
InsulKrimp Quick 190170032
Disconnect,
Female, for 14-16
(2.00-1.30mm²) Wire,
Box, Tab 4.75 x
0.81mm
InsulKrimp Quick 190170037
Disconnect,
Female, for 14-16
(2.00-1.30mm²) Wire,
Box, Tab 6.35 x
0.81mm
InsulKrimp Quick 190170043
Disconnect,
Female, for 14-16
(2.00-1.30mm²) Wire,
Box, Tab 5.21 x
0.51mm
InsulKrimp Quick 190170044
Disconnect,
Female, for 14-16

(2.00-1.30mm²) Wire,
Box, Tab 5.21 x
0.81mm
InsulKrimp Quick 190170047
Disconnect,
Female, for 10-12
(5.00-3.30mm²) Wire,
Box, Tab 6.35 x
0.81mm
Avikrimp Quick 190190001
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Box, Tab 2.79 x
0.51mm
Avikrimp Quick 190190004
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Box, Tab 2.79 x
0.81mm
Avikrimp Quick 190190006
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Box, Tab 4.75 x
0.51mm
Avikrimp Quick 190190008
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Box, Tab 4.75 x
0.81mm
Avikrimp Quick 190190012
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Box, Tab 6.35 x
0.81mm
Avikrimp Quick 190190014
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Box, Tab 5.21 x
0.51mm
Avikrimp Quick 190190015
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Box, Tab 5.21 x
0.81mm
Avikrimp Quick 190190022
Disconnect,
Female, for 14-16
(2.00-1.30mm²) Wire,
Box, Tab 2.79 x
0.51mm
Avikrimp Quick 190190025
Disconnect,
Female, for 14-16
(2.00-1.30mm²) Wire,
Box, Tab 2.79 x
0.81mm
Avikrimp Quick 190190027
Disconnect,

Female, for 14-16 (2.00-1.30mm ²) Wire, Box, Tab 4.75 x 0.51mm Avikrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm ²) Wire, Box, Tab 4.75 x 0.81mm Avikrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm ²) Wire, Box, Tab 6.35 x 0.81mm Avikrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm ²) Wire, Box, Tab 5.21 x 0.51mm Avikrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm ²) Wire, Box, Tab 5.21 x 0.81mm Avikrimp Quick Disconnect, Female, for 10-12 (5.00-3.30mm ²) Wire, Box, Tab 6.35 x 0.81mm Quixon Quick Disconnect, InsulKrimp Style, Female, Partially Insulated Red, 18-22 AWG, Loose Quixon Quick Disconnect, InsulKrimp Style, Female, Partially Insulated Blue, 14-16 AWG, Loose Quixon Quick Disconnect, Avikrimp Style, Female, Partially Insulated Red, 18-22 AWG, Loose Quixon Quick Disconnect, Avikrimp Style, Female, Partially Insulated Blue, 14-16 AWG, Loose Quixon Quick Disconnect, Avikrimp Style, Female, Fully Insulated Yellow, 10-12 AWG, Loose Avikrimp Fully Insulated Quick	<p><u>190190028</u></p> <p><u>190190031</u></p> <p><u>190190034</u></p> <p><u>190190035</u></p> <p><u>190190037</u></p> <p><u>192740002</u></p> <p><u>192740005</u></p> <p><u>192750002</u></p> <p><u>192750005</u></p> <p><u>192770008</u></p> <p><u>196060005</u></p>
---	---

Disconnect, Female,
for 10-12 AWG Wire,
Box

This document was generated on 09/15/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[64001-0200](#)