

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0640011100](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: PremiumGrade Hand Crimp Tool for Avikrimp Female Fully Insulated Quick Disconnect Terminals, 14-16 AWG

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Application Tooling
Series	207129
Comments	Type RHT
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	N/A
Tool Type	Hand Crimp Tool
UPC	756054591864
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Engineering Number RHT-5762

Reference - Drawing Numbers

Application Tooling Documents
 ATS-640011100-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

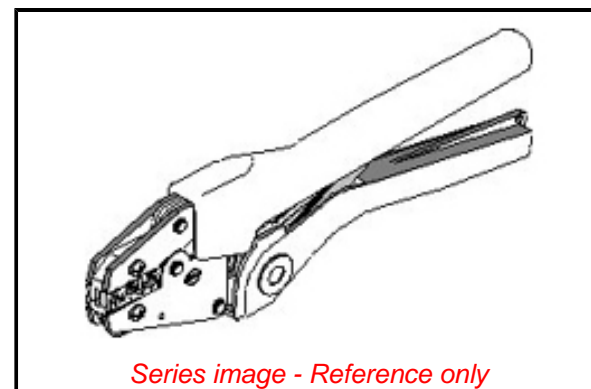

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[207129 Series](#)

Use With

Loose Piece Terminals

Application Tooling

FAQ

Description	Product #
Avikrimp Fully Insulated Quick Disconnect, Female, for 14-16 AWG Wire, Box	190020024
Avikrimp Fully Insulated Quick Disconnect, Female, for 14-16 AWG Wire, Box	190020028
Avikrimp Fully Insulated Quick Disconnect, Female, for 14-16 AWG Wire, Box	190020031
Avikrimp Fully Insulated Quick	190020034

Disconnect, Female,
for 14-16 AWG Wire,
Box

Avikrimp Fully 190020037
Insulated Quick

Disconnect, Female,
for 14-16 AWG Wire,
Box

Avikrimp Fully 190020040
Insulated Quick

Disconnect, Female,
for 14-16 AWG Wire,
Box

Avikrimp Fully 190020042
Insulated Quick

Disconnect, Female,
for 14-16 AWG Wire,
Box

Quixon Quick 192770005

Disconnect, Avikrimp
Style, Female, Fully
Insulated Blue, 14-16
AWG, Loose

This document was generated on 07/29/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[64001-1100](#)