

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0640014300](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: PremiumGrade Hand Crimp Tool for Avikrimp Fully Pre-Insulated and Insulated Quick Disconnect Flags, 14-22 AWG

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Application Tooling
Series	207129
Comments	Type RHT
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	N/A
Tool Type	Hand Crimp Tool
UPC	822348077434
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Engineering Number RHT-AFIFG

Reference - Drawing Numbers

Application Tooling Documents
 ATS-640014300-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

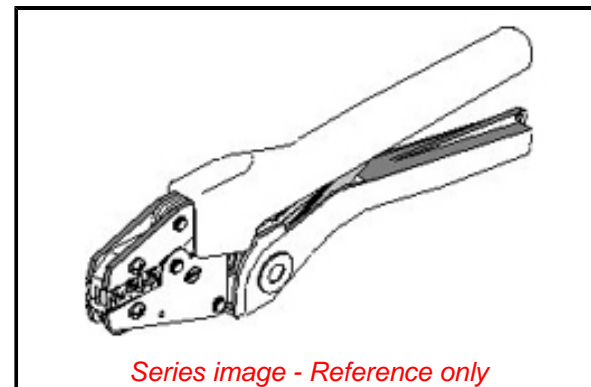

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[207129 Series](#)

Use With

Loose Piece Terminals

Application Tooling | [FAQ](#)

Description	Product #
--------------------	------------------

Avikrimp Quick Disconnect, for 18-22 AWG Wire, Female Flag, Tab 6.35 x 0.81mm	190060001
---	---------------------------

Avikrimp Quick Disconnect, for 18-22 AWG Wire, Female Flag, Tab 4.75 x 0.51mm	190060005
---	---------------------------

Flag Avikrimp Quick Disconnect, Female, for 18-22 (0.80-0.35mm ²) Wire, Box, Tab 4.75 x 0.81mm	190060008
--	---------------------------

Avikrimp Quick 190060011
Disconnect, for 14-16
AWG Wire, Female
Flag, Tab 6.35 x
0.81mm
Avikrimp Quick 190060015
Disconnect, for 14-16
AWG Wire, Female
Flag, Tab 4.75 x
0.51mm
Flag Avikrimp 190060017
Quick Disconnect,
Female, for 14-16
(2.00-1.30mm²) Wire,
Box, Tab 4.75 x
0.81mm

This document was generated on 07/26/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[64001-4300](#)