

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0640014500](#)  
**Status:** **Active**  
**Overview:** [Application Tooling](#)  
**Description:** PremiumGrade Hand Crimp Tool

**Documents:**  
[RoHS Certificate of Compliance \(PDF\)](#)

**General**


Product Family	Application Tooling
Series	<a href="#">207129</a>
Comments	ServiceGrade Hand Tool <a href="#">640160042</a> Type RHT
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	<a href="mailto:applicationtooling@molex.com">applicationtooling@molex.com</a>
Overview	<a href="#">Application Tooling</a>
Product Name	N/A
Tool Type	Hand Crimp Tool
UPC	822348114870
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

**Material Info**

Engineering Number RHT-5771

**Reference - Drawing Numbers**

Application Tooling Documents  
 ATS-640014500-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

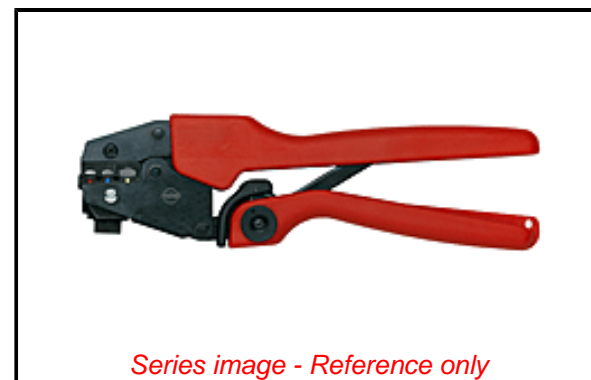

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Contained Per - ED/30/2017 (7 July 2017)

**Halogen-Free Status**

**Not Relevant**

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

[207129](#) Series

**Use With**

Loose Piece Terminals

**Application Tooling Description**

**FAQ Product #**

Perma-Seal Male Quick Disconnect Tab for 18-22 AWG Wire, Tab Size 6.35 x 0.81mm, Bag	<a href="#">191640015</a>
Perma-Seal Female Quick Disconnect Receptacle for 18-22 AWG Wire, Tab Size 6.35 x 0.81mm	<a href="#">191640017</a>
Perma-Seal Male Quick Disconnect Tab for 14-16 AWG Wire, Tab Size 6.35 x 0.81mm, Bag	<a href="#">191640048</a>
Perma-Seal Female Quick Disconnect	<a href="#">191640050</a>

Receptacle for 14-16  
AWG Wire, Tab Size  
6.35 x 0.81mm

This document was generated on 07/31/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[64001-4500](#)