

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0640014700](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: PremiumGrade Hand Crimp Tool for Industrial Terminals 14-22 AWG (see ATS)

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Application Tooling
Series	207129
Comments	Type RHT
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	N/A
Tool Type	Hand Crimp Tool
UPC	822348113705
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Engineering Number RHT-2761-CC

Reference - Drawing Numbers

Application Tooling Documents
 TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

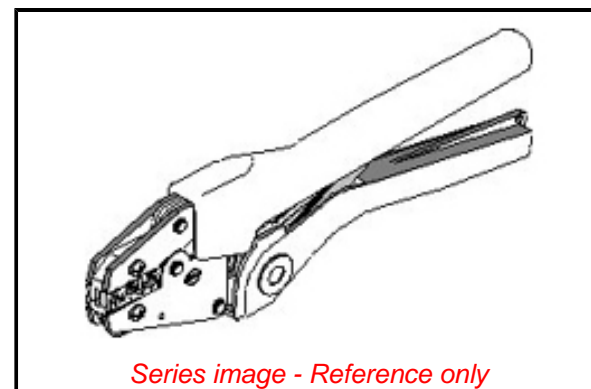

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[207129 Series](#)

Use With

Loose Piece Terminals

Application Tooling

Description

FAQ

Product #

InsulKrimp Fully [190040001](#)

Insulated Coupler, Male, for 18-22 AWG Wire, Box

InsulKrimp Fully [190040005](#)

Insulated Coupler, Male, for 14-16 AWG Wire, Box

InsulKrimp Fully [190050001](#)

Insulated Coupler, Female, for 18-22 AWG Wire, Box

InsulKrimp Fully [190050005](#)

Insulated Coupler, Female, for 14-16 AWG Wire, Box

Perma-Seal Male 191640015
Quick Disconnect
Tab for 18-22 AWG
Wire, Tab Size 6.35
x 0.81mm, Bag
Perma-Seal Female 191640017
Quick Disconnect
Receptacle for 18-22
AWG Wire, Tab Size
6.35 x 0.81mm
Perma-Seal Male 191640048
Quick Disconnect
Tab for 14-16 AWG
Wire, Tab Size 6.35
x 0.81mm, Bag
Perma-Seal Female 191640050
Quick Disconnect
Receptacle for 14-16
AWG Wire, Tab Size
6.35 x 0.81mm
Perma-Seal Snap 191640052
Receptacle for 18-22
AWG Wire, Diameter
3.96mm
Perma-Seal Snap 191640053
Receptacle for 18-22
AWG Wire, Diameter
4.57mm

This document was generated on 10/07/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[64001-4700](#)