

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0640016400](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: Hand Crimp Tool

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)


General

Product Family	Application Tooling
Series	207129
Comments	Type RHT
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	N/A
Tool Type	Hand Crimp Tool
UPC	822350736930
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers
Application Tooling Documents

ATS-640016400-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

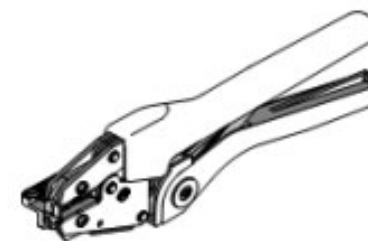

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Not Relevant

Not Relevant

Not Contained

Search Parts in this Series

[207129 Series](#)

Use With

Loose Piece Terminals

Application Tooling | **FAQ**

Description	Product #
Avikrimp Piggyback Quick Disconnect, Tab 6.35 x 0.81mm, 18-22 AWG, Red Insulator, Loose	190120029
Avikrimp Piggyback Quick Disconnect, Tab 6.35 x 0.81mm, 18-22 AWG, Red, Insulator, Tape	190120030
Avikrimp Piggyback Quick Disconnect, Tab 6.35 x 0.81mm, 14-16 AWG, Blue Insulator, Loose	190120031
Avikrimp Piggyback Quick Disconnect,	190120032

Tab 6.35 x 0.81mm,
14-16 AWG, Blue
Insulator, Tape
Avikrimp Piggyback 190120033
Quick Disconnect,
Tab 6.35 x 0.81mm,
10-12 AWG, Yellow
Insulator, Loose
Avikrimp Fully 190120034
Insulated Piggyback
Quick Disconnect,
Tab 6.35 x 0.81mm,
10-12 AWG, Yellow
Insulator, Tape
Avikrimp Fully 196020004
Insulated Piggyback
Quick Disconnect,
Tab 6.35 x 0.81mm,
18-22 AWG, Red
Insulator, Loose
Avikrimp Fully 196020005
Insulated Piggyback
Quick Disconnect,
Tab 6.35 x 0.81mm,
14-16 AWG, Blue
Insulator, Loose
Avikrimp Fully 196020006
Insulated Piggyback
Quick Disconnect,
Tab 6.35 x 0.81mm,
10-12 AWG, Loose
Piece in Bag
Avikrimp Fully 196020010
Insulated Piggyback
Quick Disconnect,
Tab 6.35 x 0.81mm,
18-22 AWG, Red
Insulator, Tape
Avikrimp Fully 196020011
Insulated Piggyback
Quick Disconnect,
Tab 6.35 x 0.81mm,
14-16 AWG, Blue
Insulator, Tape
Avikrimp Fully 196020012
Insulated Piggyback
Quick Disconnect,
Tab 6.35 x 0.81mm,
10-12 AWG, Yellow
Insulator, Tape

This document was generated on 10/07/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[64001-6400](#)