

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0640031100**  
**Status:** **Active**  
**Overview:** Application Tooling  
**Description:** Hand Crimp Tool

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

**General**


Product Family	Application Tooling
Series	<u>207129</u>
Comments	Type RHT
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	<a href="mailto:applicationtooling@molex.com">applicationtooling@molex.com</a>
Overview	<u>Application Tooling</u>
Product Name	N/A
Tool Type	Hand Crimp Tool
UPC	822348637232
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

**Material Info**

Engineering Number RHT-1751

**Reference - Drawing Numbers**

Application Tooling Documents  
ATS-640031100-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

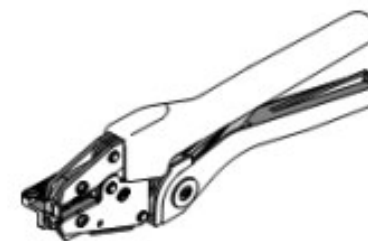

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Relevant**

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

207129 Series

**Use With**

Loose Piece Terminals

**Application Tooling** | **FAQ**

**Description** | **Product #**

Krimptite Quick Disconnect, Female, for 18-22 (0.80-0.35mm<sup>2</sup>) Wire, Box, Tab 2.79 x 0.51mm [190160001](#)

Krimptite Quick Disconnect, Female, for 18-22 (0.80-0.35mm<sup>2</sup>) Wire, Box, Tab 2.79 x 0.81mm [190160003](#)

Krimptite Quick Disconnect, Female, for 18-22 (0.80-0.35mm<sup>2</sup>) Wire, Box, Tab 4.75 x 0.51mm [190160005](#)

Krimptite Quick Disconnect, Female, for 18-22 (0.80-0.35mm<sup>2</sup>) Wire, Box, Tab 4.75 x 0.51mm

Krimptite Quick Disconnect, Female, for 18-22 (0.80-0.35mm <sup>2</sup> ) Wire, Box, Tab 6.35 x 0.81mm	<u>190160009</u>
Krimptite Quick Disconnect, Female, for 14-16 (2.00-1.30mm <sup>2</sup> ) Wire, Box, Tab 2.79 x 0.51mm	<u>190160035</u>
Krimptite Quick Disconnect, Female, for 14-16 (2.00-1.30mm <sup>2</sup> ) Wire, Box, Tab 2.79 x 0.81mm	<u>190160037</u>
Krimptite Quick Disconnect, Female, for 14-16 (2.00-1.30mm <sup>2</sup> ) Wire, Box, Tab 4.75 x 0.51mm	<u>190160039</u>
Krimptite Quick Disconnect, Female, for 14-16 (2.00-1.30mm <sup>2</sup> ) Wire, Box, Tab 4.75 x 0.81mm	<u>190160040</u>
Krimptite Quick Disconnect, Female, for 14-16 (2.00-1.30mm <sup>2</sup> ) Wire, Box, Tab 6.35 x 0.81mm	<u>190160111</u>
Krimptite Snap Plug Receptacle, for 18-22 AWG Wire, Box, 16.26mm Length	<u>190370002</u>
Krimptite Snap Plug Receptacle, for 14-16 AWG Wire, Box, 16.26mm Length	<u>190370004</u>
Krimptite Snap Plug Receptacle, for 14-16 AWG Wire, Box, 17.80mm Length	<u>190370006</u>
Krimptite Snap Plug Receptacle, for 18-22 AWG Wire, Box, 17.80mm Length	<u>190370015</u>
Krimptite Quick Disconnect, Female, Steel, 483°C (900° F), 14-16 AWG, Tab 6.35mm	<u>192030390</u>
Quixon Quick Disconnect, Krimptite Style, Female, Un-	<u>192730007</u>

insulated, 18-20  
AWG, Loose  
Quixon Quick 192730008  
Disconnect, Krimptite  
Style, Female, Un-  
insulated, 14-16  
AWG, Loose

This document was generated on 07/29/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[64003-1100](#)