

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0640057400](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: Power Crimp Tool Head for Terminals 10-22 AWG Wire

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General

| | |
|--------------------------------|---|
| Product Family | Application Tooling |
| Series | 207129 |
| Comments | See Tooling Specification (PDF) Above. Type: AT |
| Function | Crimp |
| Geographic Area | Global |
| Level of Automation | Automatic |
| More Detailed Tech Information | applicationtooling@molex.com |
| Overview | Application Tooling |
| Product Name | N/A |
| Tool Type | Battery Powered Hand Tool |
| UPC | 883906134501 |
| Warranty Disclaimer | CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified. |


Physical

Net Weight 0.001/kg

Material Info

Reference - Drawing Numbers

Application Tooling Documents [ATS-640057400-001](#)

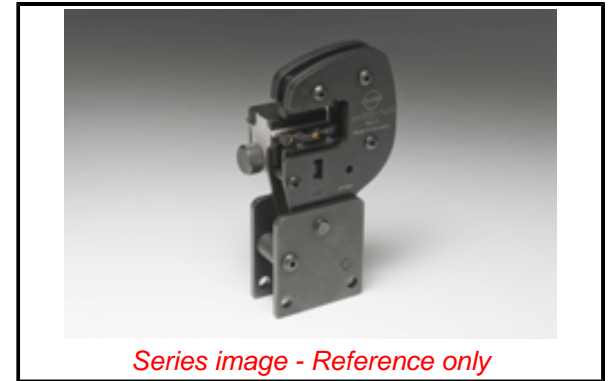

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[207129](#) Series

Use With

Battery Powered Crimping Tool [638160270](#) ,
[638160280](#)
 Electric Crimping Machine
[638161500](#)

Application Tooling Description

FAQ Product #

| | |
|--|---------------------------|
| Perma-Seal Ring Tongue Terminal for 18-22 AWG Wire, Stud Size 10 (M5) | 191640003 |
| Perma-Seal Ring Tongue Terminal for 18-22 AWG Wire, Stud Size 1/4" (M6) | 191640004 |
| Perma-Seal Ring Tongue Terminal for 18-22 AWG Wire, Stud Size 3/8" (M9) | 191640005 |
| Perma-Seal Spade Tongue Terminal for 18-22 AWG Wire, Stud Size 6 (M3.5), Bag | 191640006 |

Perma-Seal Spade 191640007
Tongue Terminal for
18-22 AWG Wire,
Stud Size 8 (M4),
Bag

Perma-Seal Spade 191640008
Tongue Terminal for
18-22 AWG Wire,
Stud Size 10 (M5),
Bag

Perma-Seal 3-Way 191640011
Connector Assembly
for 18-22 AWG Wire

Perma-Seal Butt 191640013
Splice for 18-22
AWG Wire

Perma-Seal Butt 191640014
Splice for 18-22
AWG Wire, Mylar
Tape Carrier

Perma-Seal Ring 191640020
Tongue Terminal for
14-16 AWG Wire,
Stud Size 3/8" (M9)

Perma-Seal Hook 191640021
Tongue Terminal for
14-16 AWG Wire,
Stud Size 10 (M5)

Perma-Seal Ring 191640026
Tongue Terminal for
14-16 AWG Wire,
Stud Size 1/4" (M6)

Perma-Seal Ring 191640027
Tongue Terminal for
14-16 AWG Wire,
Stud Size 5/16" (M8)

Perma-Seal Spade 191640028
Tongue Terminal
for 14-16 AWG
Wire, Stud Size 6
(M3.5),Bag

Perma-Seal Spade 191640029
Tongue Terminal for
14-16 AWG Wire,
Stud Size 8 (M4)

Perma-Seal Spade 191640030
Tongue Terminal for
14-16 AWG Wire,
Stud Size 10 (M5)

Perma-Seal Ring 191640032
Tongue Terminal for
14-16 AWG Wire,
Stud Size 6 (M3.5)

Perma-Seal Ring 191640033
Tongue Terminal for
14-16 AWG Wire,
Stud Size 8 (M4)

Perma-Seal Ring 191640034
Tongue Terminal for
14-16 AWG Wire,
Stud Size 10 (M5)

Perma-Seal 3-Way 191640042
Connector Assembly
for 14-16 AWG Wire

| | |
|---|------------------|
| Perma-Seal Step Down Butt Splice for 14-16 AWG to 18-22 AWG Wire | <u>191640043</u> |
| Perma-Seal Butt Splice for 14-16 AWG Wire | <u>191640044</u> |
| Perma-Seal Butt Splice for 14-16 AWG Wire, Mylar Tape Carrier | <u>191640045</u> |
| Perma-Seal Butt Splice for 10-12 AWG Wire | <u>191640056</u> |
| Perma-Seal Butt Splice for 10-12 AWG Wire, Mylar Tape Carrier | <u>191640057</u> |
| Perma-Seal Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 1/2" (M12) | <u>191640058</u> |
| Perma-Seal Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 6 (M3.5) | <u>191640061</u> |
| Perma-Seal Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 8 (M4) | <u>191640062</u> |
| Perma-Seal Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 10 (M5) | <u>191640065</u> |
| Perma-Seal Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 1/4" (M6) | <u>191640066</u> |
| Perma-Seal Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 5/16" (M8) | <u>191640067</u> |
| Perma-Seal Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 3/8" (M9) | <u>191640068</u> |
| Perma-Seal Spade Tongue Terminal for 10-12 AWG Wire, Stud Size 6 (M3.5) | <u>191640069</u> |
| Perma-Seal Spade Tongue Terminal for 10-12 AWG Wire, Stud Size 8 (M4) | <u>191640070</u> |
| Perma-Seal 3-Way Connector Assembly for 10-12 AWG Wire | <u>191640074</u> |
| Perma-Seal Step Down Butt Splice from 10-12 AWG to 14-16 AWG, Bag | <u>191640077</u> |
| Perma-Seal Ring Tongue Terminal for 18-22 AWG Wire, | <u>191640085</u> |

Stud Size 6 (M3.5),
Bag
Perma-Seal Ring 191640086
Tongue Terminal for
18-22 AWG Wire,
Stud Size 8 (M4)
Perma-Seal Hook 191640141
Tongue Terminal for
14-16 AWG Wire,
Stud Size 6 (M3.5)
Perma-Seal Hook 191640142
Tongue Terminal for
14-16 AWG Wire,
Stud Size 8 (M4)
Perma-Seal Ring 191640306
Tongue Terminal for
18-22 AWG Wire,
Stud Size 10 (M5),
Mylar Tape Carrier
Perma-Seal Ring 191640307
Tongue Terminal for
14-16 AWG Wire,
Stud Size 3/8" (M9),
Mylar Tape Carrier
Perma-Seal Ring 191640308
Tongue Terminal for
14-16 AWG Wire,
Stud Size 1/4" (M6),
Mylar Tape Carrier
Perma-Seal Ring 191640309
Tongue Terminal for
14-16 AWG Wire,
Stud Size 5/16" (M8),
Mylar Tape Carrier
Perma-Seal Ring 191640310
Tongue Terminal for
14-16 AWG Wire,
Stud Size 6 (M3.5),
Mylar Tape Carrier
Perma-Seal Ring 191640311
Tongue Terminal for
14-16 AWG Wire,
Stud Size 8 (M4),
Mylar Tape Carrier
Perma-Seal Ring 191640312
Tongue Terminal for
14-16 AWG Wire,
Stud Size 10 (M5),
Mylar Tape Carrier
Perma-Seal Ring 191640316
Tongue Terminal for
10-12 AWG Wire,
Stud Size 10 (M5),
Mylar Tape Carrier
Perma-Seal Ring 191640317
Tongue Terminal for
10-12 AWG Wire,
Stud Size 1/4" (M6),
Mylar Tape Carrier
Perma-Seal Ring 191640318
Tongue Terminal for
10-12 AWG Wire,
Stud Size 5/16" (M8),
Mylar Tape Carrier

Perma-Seal Ring 191640419
Tongue Terminal for
18-22 AWG Wire,
Stud Size 8 (M4),
Mylar Tape Carrier
Perma-Seal Spade 191640948
Tongue Terminal
for 14-16 AWG
Wire, Stud Size 6
(M3.5), Tape on Reel

This document was generated on 07/27/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[64005-7400](#)