

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0705450054](#)
Status: **Active**
Overview: [SL Modular Connectors](#)
Description: 2.54mm Pitch SL Header, Single Row 3.05mm Pocket Vertical, Shrouded, with Press-fit Plastic Peg, 20 Circuits, 0.38µm Gold (Au) Selective Plating, Tin (Sn) PC Tail Plating

Documents:

| | |
|--|---|
| 3D Model | Product Specification PS-70541-001 (PDF) |
| Drawing (PDF) | Packaging Specification PK-70873-0014-001 (PDF) |
| 3D Model (PDF) | Test Summary TS-70541-100-001 (PDF) |
| Product Specification PS-70400-001 (PDF) | RoHS Certificate of Compliance (PDF) |

Agency Certification

CSA LR19980

General


| | |
|----------------|---------------------------------------|
| Product Family | PCB Headers |
| Series | 70545 |
| Application | Signal, Wire-to-Board |
| Overview | SL Modular Connectors |
| Product Name | SL |
| UPC | 800753597761 |

Physical

| | |
|--------------------------------|--------------------------------|
| Breakaway | No |
| Circuits (Loaded) | 20 |
| Circuits (maximum) | 20 |
| Color - Resin | Black |
| Durability (mating cycles max) | 50 |
| Flammability | 94V-0 |
| Glow-Wire Capable | No |
| Lock to Mating Part | Yes |
| Material - Metal | Brass, Phosphor Bronze |
| Material - Plating Mating | Gold |
| Material - Plating Termination | Tin |
| Material - Resin | High Temperature Thermoplastic |
| Net Weight | 3.853/g |
| Number of Rows | 1 |
| Orientation | Vertical |
| PC Tail Length | 3.30mm |
| PCB Locator | Yes |
| PCB Retention | Yes |
| PCB Thickness - Recommended | 1.60mm |
| Packaging Type | Tube |
| Pitch - Mating Interface | 2.54mm |
| Plating min - Mating | 0.381µm |
| Plating min - Termination | 1.905µm |
| Polarized to Mating Part | Yes |
| Shrouded | Fully |
| Stackable | No |
| Surface Mount Compatible (SMC) | Yes |
| Temperature Range - Operating | -40° to +105°C |
| Termination Interface: Style | Through Hole |

Electrical

| | |
|-------------------------------|------|
| Current - Maximum per Contact | 3.0A |
| Voltage - Maximum | 250V |

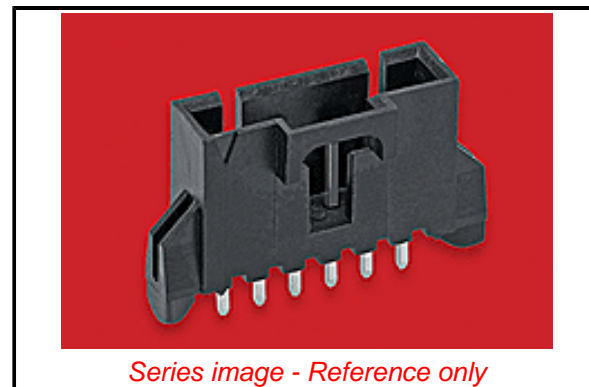

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[70545 Series](#)

Mates With

SL Crimp Housing [70066](#) Option N, [70066](#) Option G, [70066](#) Option A, [70430](#) Option G, [70400](#) Option G

Solder Process Data

Lead-free Process Capability

WAVE

Material Info

Engineering Number

A-70545-0054

Reference - Drawing Numbers

Packaging Specification

PK-70873-0014-001

Product Specification

PS-70400-001, PS-70541-001

Sales Drawing

SDA-70545-XXXX-001, SDA-70545-XXXX-002,
SDA-70545-XXXX-003

Test Summary

TS-70541-100-001

This document was generated on 12/14/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[70545-0054](#)