

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0713085200**  
**Status:** **Active**  
**Overview:** C-Grid Connector Products  
**Description:** 2.54mm Pitch C-Grid Breakaway Header, Surface Mount, Dual Row, Vertical, 100 Circuits, 0.38µm Gold (Au) Selective Plating, with 3.30mm PCB Locator Pegs, with 8.13mm Mating Pin Length

**Documents:**

<a href="#">3D Model</a>	<a href="#">Packaging Specification 713080000-PK-000 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">Packaging Specification 713080001-PK-000 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Packaging Specification 713080002-PK-000 (PDF)</a>
<a href="#">Product Specification PS-71308-001 (PDF)</a>	<a href="#">Packaging Specification 713080003-PK-000 (PDF)</a>
<a href="#">Application Specification 713080001-AS-000 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**Agency Certification**

CSA LR19980

**General**

Product Family PCB Headers  
 Series [71308](#)  
 Application Board-to-Board, Signal, Wire-to-Board  
 Overview [C-Grid Connector Products](#)  
 Product Name C-Grid  
 UPC 822348739363

**Physical**


Breakaway Yes  
 Circuits (Loaded) 100  
 Circuits (maximum) 100  
 Color - Resin Black  
 Durability (mating cycles max) 50  
 Flammability 94V-0  
 Glow-Wire Capable No  
 Lock to Mating Part None  
 Material - Metal Phosphor Bronze  
 Material - Plating Mating Gold  
 Material - Plating Termination Tin  
 Material - Resin High Temperature Thermoplastic  
 Net Weight 8.295/g  
 Number of Rows 2  
 Orientation Vertical  
 PCB Locator Yes  
 PCB Retention Yes  
 Packaging Type Tube  
 Pitch - Mating Interface 2.54mm  
 Polarized to Mating Part No  
 Polarized to PCB No  
 Shrouded No  
 Stackable Yes  
 Temperature Range - Operating -40° to +105°C  
 Termination Interface: Style Surface Mount

**Electrical**

Current - Maximum per Contact 3.0A  
 Voltage - Maximum 250V

**Solder Process Data**

Lead-freeProcess Capability REFLOW

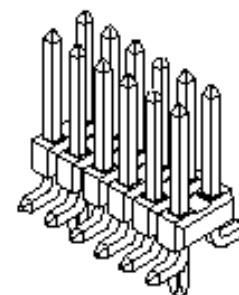

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[71308 Series](#)

Process Temperature max. C 260

**Material Info**

**Reference - Drawing Numbers**

Application Specification	713080001-AS-000
Packaging Specification	713080000-PK-000, 713080001-PK-000, 713080002-PK-000, 713080003-PK-000
Product Specification	PS-71308-001
Sales Drawing	713080000-SD-000

This document was generated on 07/28/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[71308-5200](#)