

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0745470403](#)
Status: **Active**
Overview: iPass™ Connector System
Description: External iPass™ Mini Multi-Lane SATA X4 Cable Assembly, 26 Circuits, 28 AWG, 3.0m Length, Key 7

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	74547
Assembly Configuration	Dual Ended Connectors
Comments	M Cable, SATA
Connector to Connector	Mini SAS-to-Serial ATA
Overview	iPass™ Connector System
Product Name	iPass™, Mini Multi-Lane, SAS, X4
UPC	822350328531


Physical

Cable Length	3.0m
Circuits (Loaded)	26
Gender	Plug
Lock to Mating Part	Yes
Material - Metal	Stainless Steel, Steel
Net Weight	315.000/g
Packaging Type	Bag
Pitch - Mating Interface	0.80mm
Single Ended	No
Waterproof / Dustproof	Yes
Wire Insulation Diameter	N/A
Wire Size AWG	28
Wire/Cable Type	Parallel Pair

Electrical

Impedance	100#
Shield Type	AL Foil
Shielded	Yes
Voltage - Maximum	30V

Material Info

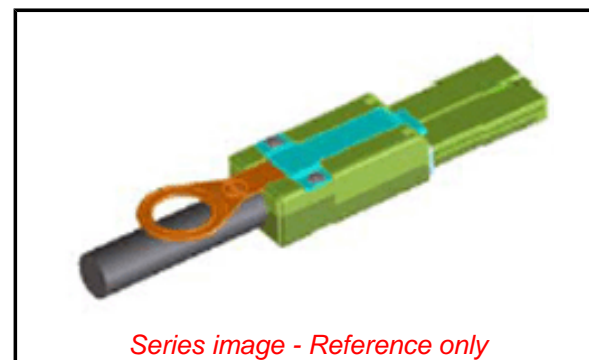

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/108/2014 (17 Dec 2014)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

China RoHS

Green Image

Not Relevant

Search Parts in this Series

[74547](#) Series

Mates With

[75586](#) iPass™ Receptacle. [74548](#) EMI Housing Assembly

Use With

[74735](#) X2 Transceiver. [74739](#) XPAK Transceiver. [74548](#) External iPass Mini Multi-Lane SAS Guide Frame

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[74547-0403](#)