

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0745470404](#)  
**Status:** **Active**  
**Overview:** iPass™ Connector System  
**Description:** External iPass™ Mini Multi-Lane SATA X4 Cable Assembly, 26 Circuits, 28 AWG, 4.0m Length, Key 7

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable Assemblies
Series	<a href="#">74547</a>
Assembly Configuration	Dual Ended Connectors
Comments	M Cable, SATA
Connector to Connector	Mini SAS-to-Serial ATA
Overview	<a href="#">iPass™ Connector System</a>
Product Name	iPass™, Mini Multi-Lane, SAS, X4
UPC	822350328548


**Physical**

Cable Length	4.0m
Circuits (Loaded)	26
Gender	Plug
Lock to Mating Part	Yes
Material - Metal	Stainless Steel, Steel
Net Weight	385.000/g
Packaging Type	Bag
Pitch - Mating Interface	0.80mm
Single Ended	No
Waterproof / Dustproof	Yes
Wire Insulation Diameter	N/A
Wire Size AWG	28
Wire/Cable Type	Parallel Pair

**Electrical**

Impedance	100#
Shield Type	AL Foil
Shielded	Yes
Voltage - Maximum	30V

**Material Info**

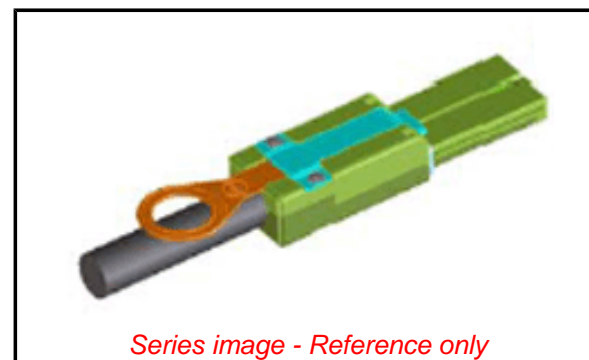

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
ED/108/2014 (17 Dec  
2014)

**Halogen-Free**

**Status**

**Not Low-Halogen**

**Need more information on product  
environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any  
non-product compliance questions.

China ROHS

ELV

**China RoHS**

Green Image

Not Relevant

**Search Parts in this Series**

[74547](#) Series

**Mates With**

[75586](#) iPass™ Receptacle. [74548](#) EMI  
Housing Assembly

**Use With**

[74735](#) X2 Transceiver. [74739](#) XPAK  
Transceiver. [74548](#) External iPass Mini  
Multi-Lane SAS Guide Frame

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[74547-0404](#)