

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0755685256](#)
Status: **Active**
Overview: [EXTreme PowerMass High-Current Connectors](#)
Description: [EXTreme PowerMass Signal Module, Plug, Right-Angle, 56 Circuits, Long PC Tails](#)

Documents:

[3D Model](#) [Product Specification PS-75431-999-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [Packaging Specification PK-46081-100-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General


Product Family PCB Headers
 Series [75568](#)
 Application Board-to-Board, Signal
 Overview [EXTreme PowerMass High-Current Connectors](#)
 Product Name EXTreme PowerMass
 UPC 800756779898

Physical

(p)ower-(s)ignal Configuration 56s - 0p
 Breakaway No
 Circuits (Loaded) 56
 Circuits (maximum) 56
 Durability (mating cycles max) 50
 First Mate / Last Break No
 Flammability 94V-0
 Glow-Wire Capable No
 Guide to Mating Part No
 Keying to Mating Part None
 Lock to Mating Part No
 Material - Plating Mating Gold
 Material - Plating Termination Tin
 Net Weight 22.220/g
 Number of Rows 8
 Orientation Right Angle
 PC Tail Length 3.84mm
 PCB Locator No
 PCB Retention None
 PCB Thickness - Recommended 2.40mm
 Packaging Type Tray
 Pitch - Mating Interface 2.50mm
 Pitch - Termination Interface 2.50mm
 Polarized to Mating Part No
 Polarized to PCB No
 Shrouded Closed Ends
 Stackable No
 Surface Mount Compatible (SMC) Yes
 Temperature Range - Operating -40° to +105°C
 Termination Interface: Style Through Hole

Electrical

Current - Maximum per Contact 3.0A
 Voltage - Maximum 50V

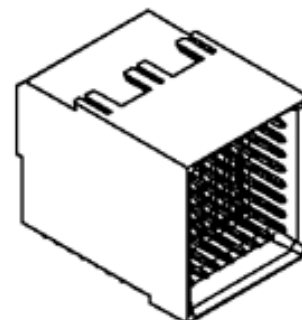

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS Not Reviewed

ELV Not Reviewed

RoHS Phthalates Not Reviewed

Search Parts in this Series

[75568](#) Series

Mates With

[75548](#) EXTreme PowerMass Receptacle

Material Info

Reference - Drawing Numbers

Packaging Specification

PK-46081-100-001

Product Specification

PS-75431-999-001

Sales Drawing

SD-75568-100-001, TS-75431-999-001

This document was generated on 07/29/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[75568-5256](#)