

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0850844808](#)
Status: **Active**
Overview: SRC - Sealed Rectangular Connectors
Description: SRC Housing, Female, Hybrid 56 Pin Mixed Power and Signal (48 x MX150 + 8 x MX150L), SPS/Nylon, Black

Documents:

Drawing (PDF)	Packaging Specification 937320001-K (PDF)
Product Specification 850700010-K (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification 937320001-P (PDF)	Product Literature (PDF)

General

Product Family	Crimp Housings
Series	85084
Application	Power, Signal, Wire-to-Wire
Overview	SRC - Sealed Rectangular Connectors
Product Literature Order No	987650-7391
Product Name	SRC
UPC	887191140520


Physical

Circuits (maximum)	56
Circuits Detail	48 x MX150™ + 8 x MX150L™
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	SPS/Nylon
Net Weight	108.880/g
Number of Rows	11
Packaging Type	Tray
Panel Mount	No
Pitch - Mating Interface	0.30mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +125°C

Material Info

Reference - Drawing Numbers

Packaging Specification	937320001-K
Product Specification	850700010-K, 937320001-P
Sales Drawing	850840700-000

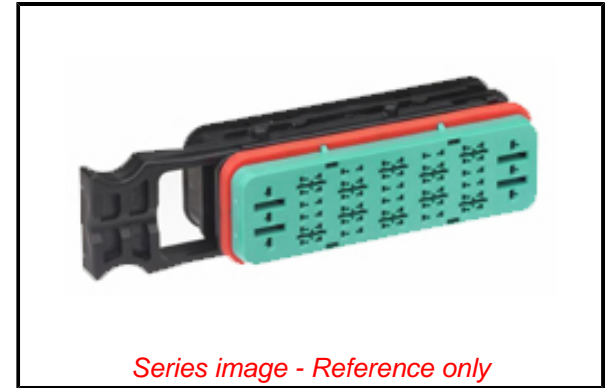

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[85084 Series](#)

Mates With

SRC Power Blade Housing [937924808](#)

Use With

MX150 Female Terminals [33012](#) . MX150L Female Terminal [19434](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[85084-4808](#)