

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0871301900**
Status: **Active**
Description: 2.50mm Pitch Cable Holder, for Discrete Wire, Flat Cable and Ribbon Cable 19 Circuits

Documents:

[3D Model](#) [Product Specification PS-87130-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980

General

Product Family Ribbon Cable / Wire Trap Connectors
Series [87130](#)
Component Type One Piece
Glow-Wire Capable No
Product Name Board-in, Cable Holder
UPC 800754784054

Physical

Circuits (Loaded) 19
Circuits (maximum) 19
Entry Angle Vertical
Flammability 94V-0
Lock to Mating Part None
Material - Plating Mating N/A
Net Weight 0.956/g
Number of Rows 1
PCB Locator Yes
PCB Retention Yes
PCB Thickness - Recommended 1.60mm
Packaging Type Bag
Pitch - Mating Interface 2.50mm
Pitch - Termination Interface 2.50mm
Polarized to Mating Part Yes
Polarized to PCB No
Shrouded Fully
Stackable No
Surface Mount Compatible (SMC) No
Temperature Range - Operating -25° to +85°C
Wire Insulation Diameter 1.60mm max.
Wire Size AWG 24, 26
Wire/Cable Type Discrete Wire, Ribbon Cable


Electrical

Current - Maximum per Contact 1.0A
Voltage - Maximum 125V

Material Info

Reference - Drawing Numbers

Product Specification PS-87130-001-001
Sales Drawing SD-87130-XX00

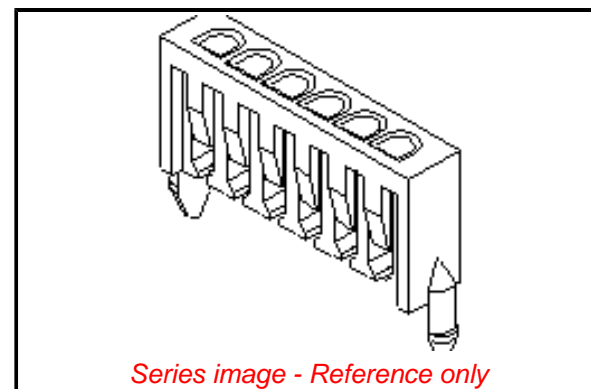

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS Not Reviewed

ELV Not Reviewed

RoHS Phthalates Not Reviewed

Search Parts in this Series

[87130 Series](#)

Mates With

N/A

Use With

Discrete Wire, Flat Cable, or Ribbon Cable

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[87130-1900](#)