


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0872630895**
Status: **Active**
Overview: Milli-Grid Connector System
Description: 2.00mm Pitch Milli-Grid Receptacle, Surface Mount, Bottom Entry, 0.76µm Gold (Au) Selective, 8 Circuits, with Pick-and-Place Cap, Embossed Tape on Reel, Lead-Free

Documents:

3D Model	Packaging Specification PK-87263-0001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-87263-300-001 (PDF)
Product Specification PS-87263-001 (PDF)	Brochure (PDF)
Application Specification 503940001-AS-000 (PDF)	RoHS Certificate of Compliance (PDF)

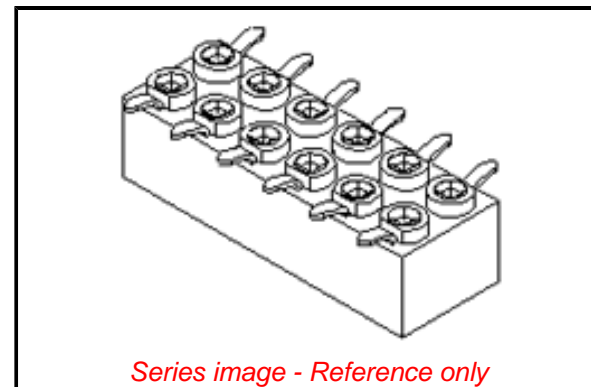

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	PCB Receptacles
Series	<u>87263</u>
Application	Board-to-Board, Signal
Overview	<u>Milli-Grid Connector System</u>
Product Name	Milli-Grid
UPC	883906507039

Physical

Circuits (Loaded)	8
Circuits (maximum)	8
Color - Resin	Black
Durability (mating cycles max)	25
Flammability	94V-0
Glow-Wire Capable	No
Lock to Mating Part	None
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	0.156/g
Number of Rows	2
Orientation	Bottom Entry
PCB Locator	Yes
PCB Retention	None
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	2.00mm
Pitch - Termination Interface	2.00mm
Plating min - Mating	0.762µm
Polarized to Mating Part	No
Polarized to PCB	Yes
Robotic Placement	Pick and Place Cap
Temperature Range - Operating	-55° to +105°C
Termination Interface: Style	Surface Mount

Electrical

Current - Maximum per Contact	1.0A
Voltage - Maximum	125V

Solder Process Data

Duration at Max. Process Temperature (seconds)	014
Lead-free Process Capability	REFLOW
Max. Cycles at Max. Process Temperature	001

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

87263 Series

Mates With

87759 Vertical, Surface Mount, Stackable PCB Headers, 87760 Right Angle, Through Hole, Stackable PCB Headers, 87758 Vertical, Through Hole, Stackable PCB Headers

Process Temperature max. C 265

Material Info

Reference - Drawing Numbers

Application Specification	503940001-AS-000
Packaging Specification	PK-87263-0001-001, PK-87263-300-001
Product Specification	PS-87263-001
Sales Drawing	SD-87263-XX2X-001

This document was generated on 08/26/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[87263-0895](#)