

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0874370543](#)
Status: **Active**
Overview: Pico-SPOX Wire-to-Board Connector System
Description: 1.50mm Pitch, Pico-SPOX PCB Header, Single Row, Vertical, Surface Mount, Tin (Sn) Plating, Friction Lock, 5 Circuits, Tape and Reel, without Cap, Beige

Documents:

3D Model (PDF)	Application Specification 874370000-AS-000 (PDF)
3D Model	Packaging Specification SPK-87437-001-001 (PDF)
Drawing (PDF)	Packaging Specification SPK-87438-001-001 (PDF)
Product Specification 874371001-PS-001 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-87437-001-001 (PDF)	

Agency Certification

UL E29179


General

Product Family	PCB Headers
Series	87437
Application	Signal, Wire-to-Board
Overview	<u>Pico-SPOX Wire-to-Board Connector System</u>
Product Name	Pico-SPOX
UPC	822348438655

Physical

Breakaway	No
Circuits (Loaded)	5
Circuits (maximum)	5
Color - Resin	Beige
Durability (mating cycles max)	10
First Mate / Last Break	No
Flammability	94V-0
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	0.254/g
Number of Rows	1
Orientation	Vertical
PCB Locator	No
PCB Retention	None
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	1.50mm
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Polarized to Mating Part	Yes
Polarized to PCB	No
Shrouded	Fully
Stackable	No
Temperature Range - Operating	-55° to +105°C
Termination Interface: Style	Surface Mount

Electrical

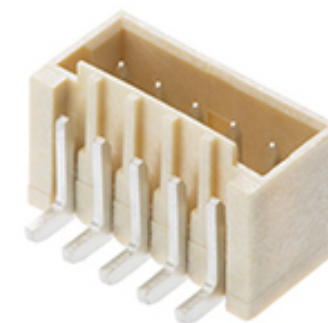

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[87437 Series](#)

Mates With

Pico-SPOX Wire-to-Board Housing [87439](#)

Current - Maximum per Contact
Voltage - Maximum

2.5A
250V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Application Specification

874370000-AS-000

Packaging Specification

SPK-87437-001-001, SPK-87438-001-001

Product Specification

874371001-PS-001, PS-87437-001-001

Sales Drawing

874370231-SD-000

This document was generated on 09/13/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[87437-0543](#)