

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0894858100](#)  
**Status:** **Active**  
**Overview:** Consumer USB Products  
**Description:** Universal Serial Bus (USB) Shielded I/O Type A Receptacle, Single Upright, Right Angle, Terminal Length 2.00mm, With Mylar, Gold (Au) Flash, Tube Package, Lead-Free

**Documents:**

[3D Model](#) [Product Specification PS-89485 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR19980  
 UL E29179

**General**


Product Family I/O Connectors  
 Series [89485](#)  
 Application Wire-to-Board  
 Comments With Mylar  
 Component Type Receptacle  
 Overview [Consumer USB Products](#)  
 Product Name USB 2.0  
 Type A  
 UPC 822348723799

**Physical**

Boot Color N/A  
 Circuits (Loaded) 4  
 Circuits (maximum) 4  
 Flammability 94V-0  
 Gender Receptacle  
 Lock to Mating Part Yes  
 Material - Plating Mating Gold  
 Material - Plating Termination Tin  
 Net Weight 2.260/g  
 Number of Rows 1  
 Orientation Upright  
 PC Tail Length 2.00mm  
 PCB Locator Yes  
 PCB Retention Yes  
 PCB Thickness - Recommended 1.60mm  
 Packaging Type Tube  
 Panel Mount No  
 Pitch - Mating Interface 2.00mm, 2.50mm  
 Pitch - Termination Interface 1.40mm  
 Polarized to Mating Part Yes  
 Polarized to PCB Yes  
 Ports 1  
 Surface Mount Compatible (SMC) No  
 Temperature Range - Operating 0°C to +50°C  
 Termination Interface: Style Through Hole  
 Waterproof / Dustproof No

**Electrical**

Current - Maximum per Contact 1.0A  
 Shield Type Full Shield

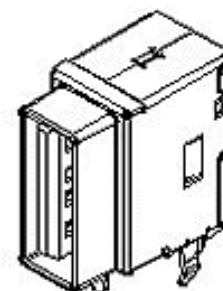

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
 -ED/79/2015 (17  
 December 2015)

**Halogen-Free**

**Status**

**Not Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

**China RoHS**

Green Image

Not Relevant

**Search Parts in this Series**

[89485](#) Series

**Mates With**

[88740](#) USB Type A Cable Plug

Shielded	Yes
Voltage - Maximum	750V AC (RMS)

**Solder Process Data**

Lead-free Process Capability	WAVE
------------------------------	------

**Material Info**

**Reference - Drawing Numbers**

Product Specification	PS-89485
Sales Drawing	SD-89485-003

This document was generated on 02/05/2016

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[89485-8100](#)