

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0903253008**
Status: **Active**
Overview: Picoflex Ribbon-Cable Connectors
Description: Picoflex PF-50 Header, PdNi with Gold Flash Plating , Vertical, Low Profile, with PCB Pegs, 8 Circuits

Documents:

| | |
|--------------------------------|--|
| 3D Model | Product Specification PS-99020-0011-001 (PDF) |
| Drawing (PDF) | Packaging Specification PK-90325-002-001 (PDF) |
| 3D Model (PDF) | RoHS Certificate of Compliance (PDF) |

Agency Certification

| | |
|-----|---------|
| CSA | LR19980 |
| UL | E29179 |

General


| | |
|----------------|---|
| Product Family | PCB Headers |
| Series | <u>90325</u> |
| Application | Signal, Wire-to-Board |
| Comments | Low Profile |
| Overview | <u>Picoflex Ribbon-Cable Connectors</u> |
| Product Name | Picoflex |
| UPC | 800753676909 |

Physical

| | |
|--------------------------------|----------------------------|
| Breakaway | No |
| Circuits (Loaded) | 8 |
| Circuits (maximum) | 8 |
| Color - Resin | Black |
| Durability (mating cycles max) | 100 |
| First Mate / Last Break | No |
| Flammability | 94V-0 |
| Glow-Wire Capable | No |
| Guide to Mating Part | No |
| Keying to Mating Part | None |
| Lock to Mating Part | Yes |
| Material - Metal | Brass |
| Material - Plating Mating | Gold over Palladium Nickel |
| Material - Resin | Polyester |
| Net Weight | 0.381/g |
| Number of Rows | 1 |
| Orientation | Vertical |
| PCB Retention | Yes |
| PCB Thickness - Recommended | 1.60mm |
| Packaging Type | Bag |
| Pitch - Mating Interface | 1.27mm |
| Pitch - Termination Interface | 1.27mm |
| Polarized to Mating Part | Yes |
| Polarized to PCB | Yes |
| Shrouded | No |
| Stackable | No |
| Surface Mount Compatible (SMC) | No |
| Temperature Range - Operating | -40° to +105°C |
| Termination Interface: Style | Through Hole |

Electrical

| | |
|-------------------------------|------|
| Current - Maximum per Contact | 1.2A |
|-------------------------------|------|

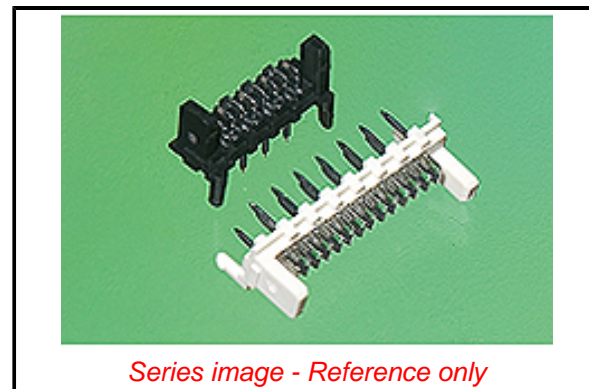

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[90325 Series](#)

Mates With

[90327 IDT Connector](#)

| | |
|------------------------------------|-------------------|
| Voltage - Maximum | 250V |
| Solder Process Data | |
| Lead-freeProcess Capability | WAVE |
| Material Info | |
| Reference - Drawing Numbers | |
| Packaging Specification | PK-90325-002-001 |
| Product Specification | PS-99020-0011-001 |
| Sales Drawing | SDA-90325-001 |

This document was generated on 08/27/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[90325-3008](#)