

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0903273384](#)
Status: **Active**
Overview: [Picoflex Ribbon-Cable Connectors](#)
Description: Picoflex PF-50, Low Profile, IDT Receptacle, 20 Circuits, White, Palladium Nickel with Gold (Au) Flash Plated, Reeling Option B

Documents:

3D Model	Product Specification PS-99020-0011-001 (PDF)
Drawing (PDF)	Packaging Specification PK-90327-001-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General


Product Family	Ribbon Cable / Wire Trap Connectors
Series	90327
Comments	Low Profile Reeling Option B
Component Type	Housing
Glow-Wire Capable	No
Overview	Picoflex Ribbon-Cable Connectors
Product Name	Picoflex
UPC	800753015142

Physical

Circuits (Loaded)	20
Circuits (maximum)	20
Color - Resin	White
Durability (mating cycles max)	100
Entry Angle	Vertical
Flammability	94V-0
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Palladium Nickel
Material - Plating Termination	Gold
Material - Resin	Polyester
Net Weight	3.034/g
Number of Rows	2
PCB Locator	No
PCB Retention	None
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	1.27mm
Pitch - Termination Interface	1.27mm
Polarized to Mating Part	Yes
Polarized to PCB	No
Shrouded	Fully
Stackable	No
Surface Mount Compatible (SMC)	N/A
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	IDT or Pierce
Wire Insulation Diameter	1.00mm max.
Wire Size AWG	26, 28
Wire/Cable Type	Ribbon Cable

Electrical

Current - Maximum per Contact	1.2A
-------------------------------	------

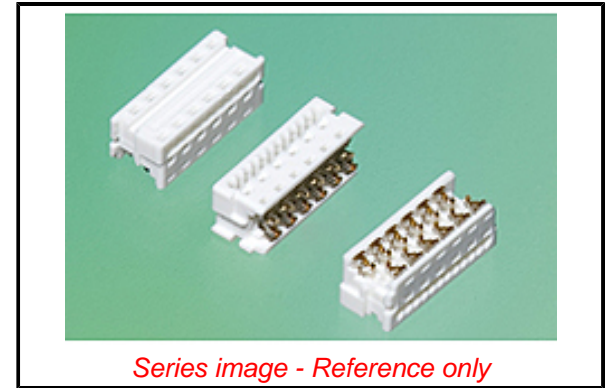

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[90327](#) Series

Mates With

Low Profile Vertical [90325](#) , Low Profile
Right Angle [90800](#) , [90715](#) , [90814](#) , [90779](#)
Vertical, [91714](#) 1.27mm Pitch Picoflex PF-50
Header

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

Extractor Tool for Connectors	621006000
-------------------------------	---------------------------

Extraction Tool for Picoflex PF-50 Connectors, 4-26 Circuits	690081070
--	---------------------------

Voltage - Maximum

250V

Material Info

Reference - Drawing Numbers

Packaging Specification

PK-90327-001-001

Product Specification

PS-99020-0011-001

Sales Drawing

SDA-90327-002

Semi-Automatic 691271001

Bench Press PB14

for 4-26 Circuit

Semi-Automatic 691271004

PB14 Bench Press

with Auto De-reeling

Assembly of De- 691275045

Tape Unit for

PB14 Part Number

691271001

This document was generated on 09/06/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[90327-3384](#)