

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010091](#)
Status: **Active**
Overview: GWconnect Heavy Duty Connectors (HDC)
Description: GWconnect Crimp Contact Insert, Female, 15-Pole, 10A, for Turned or Stamped Crimp Contacts, Size 10A «49x16»

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA	256883
UL	E249674

General

Product Family	Industrial Connectors / Enclosures
Series	93601
Component Size	10A «49X16»
Component Type	Inserts - Crimp Contact
Insert Series	S-D
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	CSA C22.2 NO. 182.3, EN 175301-801, EN 60664-1, EN 61984, UL 1977
UPC	887191869599

Physical


Durability (mating cycles max)	500
Flammability	UL 94V-0
Gender	Female
Insert Color	Grey
Material - Insert	Polycarbonate
Net Weight	31.000/g
Number of Rows	3
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	15
Temperature Range - Operating	-40° to +125°C

Electrical

Current - Maximum per Contact	10.0A
Voltage - Maximum	250V

Material Info

Engineering Number	7115.4006.0
--------------------	-------------

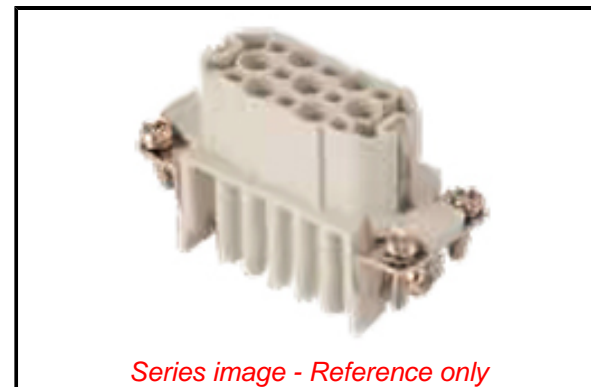

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[93601](#) Series

Mates With

[936010092](#) Female Crimp Contact Insert

Use With

Turned or Stamped Contacts - Female

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0091](#)