

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0936010100](#)  
**Status:** **Active**  
**Overview:** GWconnect Heavy Duty Connectors (HDC)  
**Description:** GWconnect Crimp Contact Insert, Female, 25-Pole, 10A, for Turned or Stamped Crimp Contacts, Size 16A «66x16», with "Z" Mark

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Industrial Connectors / Enclosures
Series	<a href="#">93601</a>
Component Size	16A «66X16»
Component Type	Inserts - Crimp Contact
Insert Series	S-D
Overview	<a href="#">GWconnect Heavy Duty Connectors (HDC)</a>
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	CSA C22.2 NO. 182.3, EN 175301-801, EN 60664-1, EN 61984, UL 1977
UPC	887191870182

**Physical**


Durability (mating cycles max)	500
Flammability	UL 94V-0
Gender	Female
Insert Color	Grey
Material - Insert	Polycarbonate
Net Weight	35.000/g
Number of Rows	3
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	25
Temperature Range - Operating	-40° to +125°C

**Electrical**

Current - Maximum per Contact	10.0A
Voltage - Maximum	250V

**Material Info**

Engineering Number	7125.4012.3
--------------------	-------------

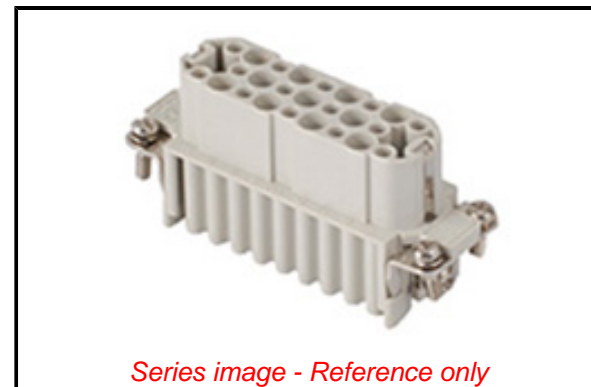

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[93601](#) Series

**Mates With**

[936010102](#) Male Crimp Contact Insert

**Use With**

Turned Contacts - Female

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0100](#)