

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010161](#)
Status: **Active**
Overview: GWconnect Heavy Duty Connectors (HDC)
Description: GWconnect Turned Crimp Contact for 16A Modules, Male, Silver (Ag) Plated Copper Alloy, 3.00mm² (12 AWG), 100 per Bag

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA	256883
UL	E249674

General

Product Family	Industrial Connectors / Enclosures
Series	93601
Contact Type	Turned Crimp
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Contacts
Product Name	GWconnect
UPC	887191873794

Physical


Gender	Male
Material - Contact	Copper Alloy
Material - Plating	Silver
Net Weight	1.200/g
Number of Grooves	1 wide
Packaging Type	Bag
Stripping Length	7.50mm
Wire Size AWG	12
Wire Size mm ²	3.00

Electrical

Current - Maximum per Contact	16.0A
-------------------------------	-------

Material Info

Engineering Number	7300.6235.0
--------------------	-------------

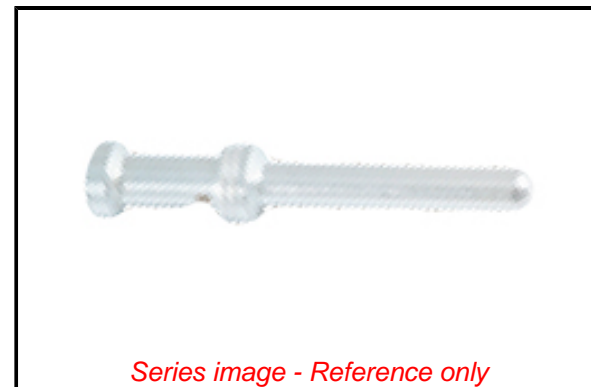

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

50 Image

Not Relevant

Not Contained

Search Parts in this Series

[93601](#) Series

Mates With

[93601](#) Female Turned Crimp Contact

Use With

S-M Modules

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0161](#)