

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010237](#)
Status: **Active**
Overview: [GWconnect Heavy Duty Connectors \(HDC\)](#)
Description: [GWconnect Crimp Contact Insert, Female, 10-Pole, 16A, for Crimp Contacts, Size 6B «44x27»](#)

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E249674

General

Product Family	Industrial Connectors / Enclosures
Series	93601
Component Size	6B «44x27»
Component Type	Inserts - Crimp Contact
Insert Series	S-EE
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
UPC	887191878454

Physical


Durability (mating cycles max)	500
Flammability	UL 94V-0
Gender	Female
Insert Color	Grey
Material - Insert	Polycarbonate
Net Weight	44.000/g
Number of Rows	4
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	10
Temperature Range - Operating	-40° to +125°C

Electrical

Current - Maximum per Contact	16.0A
Voltage - Maximum	500V

Material Info

Engineering Number	7310.6090.0
--------------------	-------------

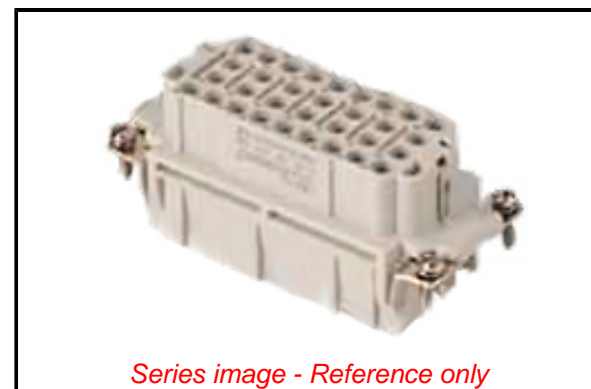

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Contained Per - ED/71/2019 (16 July 2019)

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

50 Image

Not Relevant

Not Contained

Search Parts in this Series

[93601](#) Series

Mates With

[936010244](#) Male Crimp Contact Insert

Use With

Turned Contacts - Female

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0237](#)