

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010322](#)
Status: **Active**
Overview: GWconnect Heavy Duty Connectors (HDC)
Description: GWconnect Crimp Contact Insert, Male, 32-Pole, 16A, Numbered 33-64, for Crimp Contacts, Size 32B «77x62»

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Connectors / Enclosures
Series	93601
Component Size	32B «77X62»
Component Type	Inserts - Crimp Contact
Insert Series	S-EE
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
UPC	887191883205

Physical


Durability (mating cycles max)	500
Flammability	UL 94V-0
Gender	Male
Insert Color	Grey
Material - Insert	Polycarbonate
Net Weight	59.000/g
Number of Rows	4
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	32
Temperature Range - Operating	-40° to +125°C

Electrical

Current - Maximum per Contact	16.0A
Voltage - Maximum	500V

Material Info

Engineering Number	7332.6193.0
--------------------	-------------

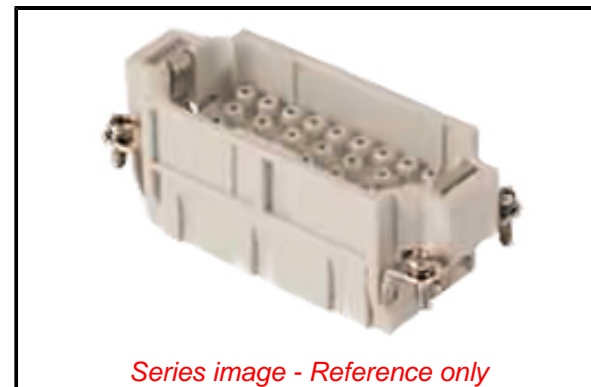

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[93601](#) Series

Mates With

[936010319](#) Female Crimp Contact Insert

Use With

Turned Contacts - Male

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0322](#)