

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0936010328](#)  
**Status:** **Active**  
**Overview:** GWconnect Heavy Duty Connectors (HDC)  
**Description:** GWconnect Crimp Contact Insert, Female, 46-Pole, 16A, Numbered 47-92, for Crimp Contacts, Size 24B «104x27»

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Industrial Connectors / Enclosures
Series	<a href="#">93601</a>
Component Size	24B «104X27»
Component Type	Inserts - Crimp Contact
Insert Series	S-EE
Overview	<a href="#">GWconnect Heavy Duty Connectors (HDC)</a>
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
UPC	887191883762

**Physical**


Durability (mating cycles max)	500
Flammability	UL 94V-0
Gender	Female
Insert Color	Grey
Material - Insert	Polycarbonate
Net Weight	86.000/g
Number of Rows	4
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	46
Temperature Range - Operating	-40° to +125°C

**Electrical**

Current - Maximum per Contact	16.0A
Voltage - Maximum	500V

**Material Info**

Engineering Number	7346.6095.0
--------------------	-------------

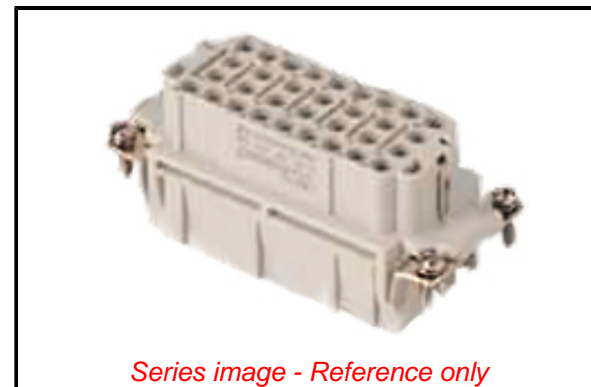

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

[93601](#) Series

**Mates With**

[936010330](#) Male Crimp Contact Insert

**Use With**

Turned Contacts - Female

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0328](#)