

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010495](#)
Status: **Active**
Overview: GWconnect Heavy Duty Connectors (HDC)
Description: GWconnect Crimp Contact Power Module, Female, 1-Pole, 200A, for Crimp Contacts, Grey

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E249674

General

Product Family Industrial Connectors / Enclosures
 Series [93601](#)
 Component Type Power Module
 Overview [GWconnect Heavy Duty Connectors \(HDC\)](#)
 Product Category Heavy Duty Connectors
 Product Name GWconnect
 UPC 887191823447

Physical


Color - Resin Grey
 Durability (mating cycles max) 500
 Flammability UL 94V-0
 Gender Female
 Material - Housing Polycarbonate
 Net Weight 18.350/g
 Packaging Type Bag
 Polarized to Mating Part Yes
 Poles 1
 Temperature Range - Operating -40° to +125°C

Electrical

Current - Maximum per Contact 200.0A
 Voltage - Maximum 1000V

Material Info

Engineering Number 7701.3056.0

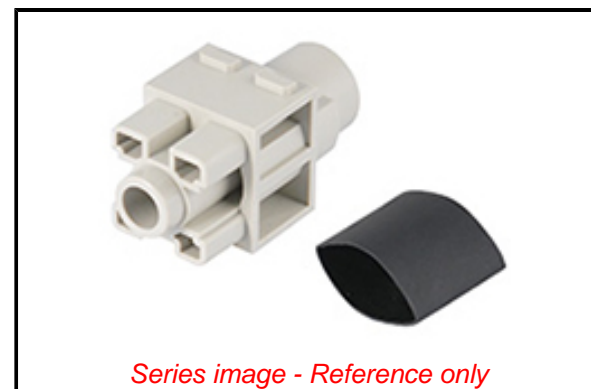

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/71/2019 (16 July
 2019)

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[93601](#) Series

Mates With

[936010496](#) Male Power Module

Use With

200.0A Turned Female Crimp Contacts

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0495](#)