

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010719](#)
Status: **Active**
Overview: GWconnect Heavy Duty Connectors (HDC)
Description: GWconnect STD - Standard, Cover for Male Inserts, Die-cast Aluminum, with 1 Lever, without Gasket, Size 3A «21x21», Grey

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA	256883
UL	E249674

General


Product Family	Industrial Connectors / Enclosures
Series	93601
Comments	With nylon wire tether line.
Component Size	3A «21x21»
Component Type	Cover
IP Rating	IP66, IP67
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Type	STD
UPC	887191844862

Physical

Cover Coating	Polyester Powder
Cover Color	Grey RAL 9002
Lock to Mating Part	Yes
Material - Cover	Die-cast Aluminum
Material - Lever	Stainless Steel
Net Weight	16.000/g
Number of Levers	1
Packaging Type	Bag

Material Info

Engineering Number	7803.6885.A
--------------------	-------------

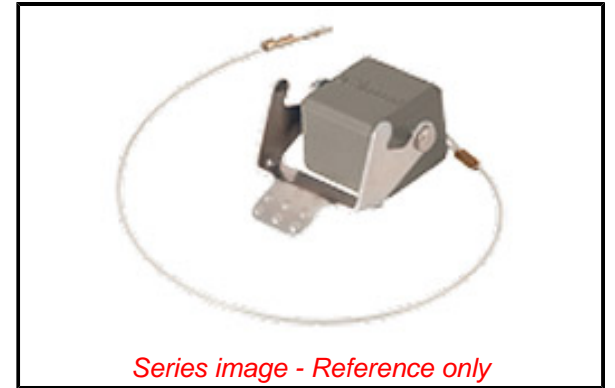

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/71/2019 (16 July 2019)

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[93601 Series](#)

Use With

Enclosures with with Size 3A «21x21» Male Inserts

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0719](#)