

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936011856](#)
Status: **Active**
Overview: [GWconnect® Heavy Duty Connectors \(HDC\)](#)
Description: GWconnect HE - Harsh Environment, Double Lever Hood, Die-cast Aluminum, with 2 Levers, Top Entry, Size 10B «57x27», with Gasket, Pg21 Thread, High Construction, Black

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA 256883
 UL E249674

General

Product Family Industrial Connectors / Enclosures
 Series [93601](#)
 Component Size 10B «57X27»
 Component Type Double Lever Hood
 IP Rating IP66, IP69
 Overview [GWconnect® Heavy Duty Connectors \(HDC\)](#)
 Product Category Heavy Duty Connectors
 Product Name GWconnect
 Standard ANSI/UL 50, ANSI/UL 50 E, CSA C22.2 No.94-1-2, EN 61984
 Type HE
 UPC 887191854014

Physical


Entry Location Top
 Hood Coating Polyester Powder
 Hood Color Black RAL 9005
 Lock to Mating Part Yes
 Material - Gasket NBR
 Material - Hood Die-cast Aluminum
 Material - Lever Galvanized Steel
 Number of Levers 2
 Packaging Type Bag
 Thread Size Pg21
 Thread Type (Pg)

Electrical

Voltage - Maximum 500V

Material Info

Engineering Number 7810.7104.6

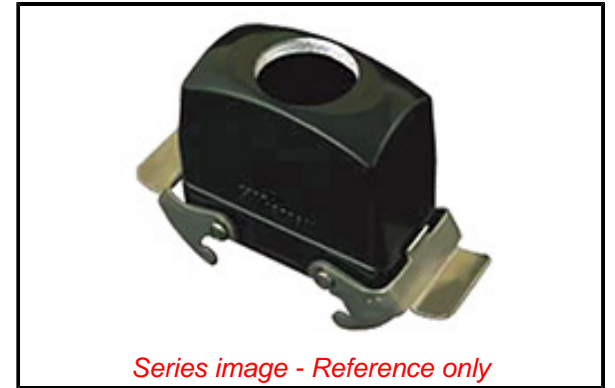

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS Not Reviewed

ELV Not Reviewed

RoHS Phthalates Not Reviewed

Search Parts in this Series

[93601 Series](#)

Use With

Size 10B «57x27» S-D, S-DD, S-E, S-ES, S-EP, S-ESHV, S-EE, S-HSB, S-K, S-M, and S-EHV Inserts

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-1856](#)