

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0936013582](#)

**Status:** **Active**

**Overview:** [GWconnect® Heavy Duty Connectors \(HDC\)](#)

**Description:** GWconnect HE - Harsh Environment, Double Lever Hood, Die-cast Aluminum, with 2 Levers, Top Entry, Size 24B «104x27», with Gasket, Pg21 Thread, High Construction, Black

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA	256883
UL	E249674

**General**

Product Family	Industrial Connectors / Enclosures
Series	<a href="#">93601</a>
Component Size	24B «104X27»
Component Type	Double Lever Hood
IP Rating	IP66, IP69
Overview	<a href="#">GWconnect® Heavy Duty Connectors (HDC)</a>
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	ANSI/UL 50, ANSI/UL 50 E, CSA C22.2 No.94-1-2, EN 61984
Type	HE
UPC	887191847139

**Physical**


Entry Location	Top
Hood Coating	Polyester Powder
Hood Color	Black RAL 9005
Lock to Mating Part	Yes
Material - Gasket	NBR
Material - Hood	Die-cast Aluminum
Material - Lever	Galvanized Steel
Number of Levers	2
Packaging Type	Bag
Thread Size	Pg21
Thread Type	(Pg)

**Electrical**

Voltage - Maximum	500V
-------------------	------

**Material Info**

Engineering Number	7824.6437.6
--------------------	-------------

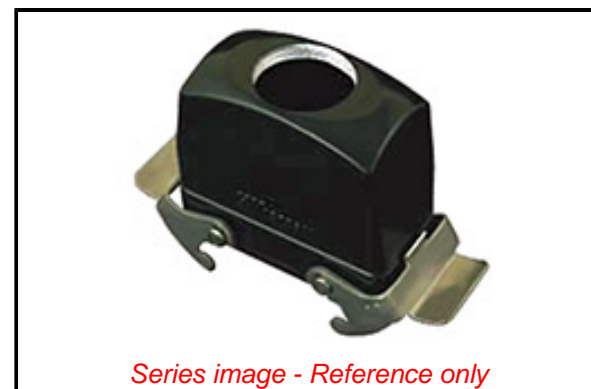

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

**Search Parts in this Series**

[93601](#) Series

**Use With**

Size 24B «104x27» S-D, S-DD, S-E, S-ES, S-EP, S-EE, S-HSB, S-K and S-M Inserts

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-3582](#)