

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936014369](#)
Status: **Active**
Overview: [GWconnect Heavy Duty Connectors \(HDC\)](#)
Description: GWconnect STD - Standard, Double Lever Bulkhead Mount Housing, Die-cast Aluminum, with 2 Levers, with Gasket, Size 32B «77x62», Grey

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA 256883
 UL E249674

General

Product Family Industrial Connectors / Enclosures
 Series [93601](#)
 Component Size 32B «77X62»
 Component Type Double Lever Bulkhead Housing
 IP Rating IP66
 Overview [GWconnect Heavy Duty Connectors \(HDC\)](#)
 Product Category Heavy Duty Connectors
 Product Name GWconnect
 Standard ANSI/UL 50, ANSI/UL 50 E, CSA C22.2 No.94-1-2, EN 61984
 Type STD
 UPC 887191894652

Physical


Housing Coating Polyester Powder
 Housing Color Grey RAL 7037
 Lock to Mating Part Yes
 Material - Gasket NBR
 Material - Housing Die-cast Aluminum
 Material - Lever Galvanized Steel
 Mounting Style Bulkhead
 Net Weight 236.000/g
 Number of Levers 2
 Packaging Type Bag
 Thread Size N/A
 Thread Type N/A

Electrical

Voltage - Maximum 500V

Material Info

Engineering Number 7832.6415.0

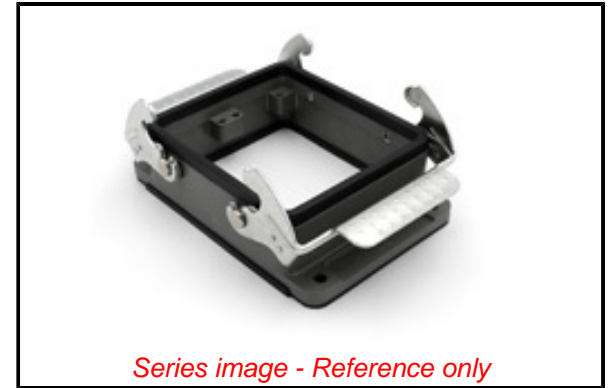

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/71/2019 (16 July 2019)

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[93601](#) Series

Use With

Size 32B «77x62» S-D, S-DD, S-E, S-EE, S-EP, S-ES, S-HSB, S-ESHV, S-K, S-M, and S-EHV Inserts

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-4369](#)