

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0936030093](#)  
**Status:** **Active**  
**Overview:** [GWconnect Heavy Duty Connectors \(HDC\)](#)  
**Description:** [GWconnect Connector Kit, 24 Pole, Series S-E Female-Male Inserts, M25 Die-cast Aluminum Hood-Side Entry, Surface Mount Housing-Vertical, 2 Lever, Size 24B «104x27», Grey](#)

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

**Kit components**

Kit Components [936013770](#) M25 Hood, [936010307](#) Male Insert, [936010297](#) Female Insert, [936013522](#) SMT Vertical Housing

**General**

Product Family Industrial Connectors / Enclosures  
 Series [93603](#)  
 Component Size 24B «104X27»  
 Component Type Connector Kit - Female+Male  
 Insert Series S-E  
 Overview [GWconnect Heavy Duty Connectors \(HDC\)](#)  
 Product Category Heavy Duty Connectors  
 Product Name GWconnect  
 UPC 887191865720

**Physical**


Lock to Mating Part Yes  
 Mounting Style Surface Mount  
 Net Weight 795.000/g  
 Packaging Type Bag  
 Thread Size M25  
 Thread Type (M) Metric

**Electrical**

Current - Maximum per Contact 16.0A  
 Voltage - Maximum 500V

**Material Info**

Engineering Number 7924.7762.0

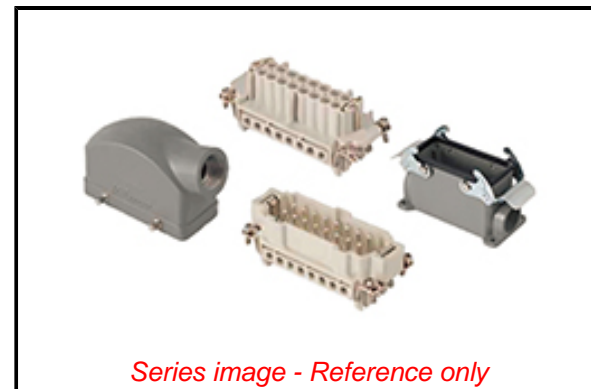

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Contained Per - ED/71/2019 (16 July 2019)  
 lead

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

50 Image

Not Relevant

Not Contained

**Search Parts in this Series**

[93603](#) Series

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93603-0093](#)