

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936060089](#)
Status: **Active**
Overview: GWconnect Heavy Duty Connectors (HDC)
Description: GWconnect Patch Cord Cable Assembly, CAT6 Plug-to-Plug, 8P4C Wiring, Fully Shielded, 10.0m

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Industrial Connectors / Enclosures
Series	93606
Color - Cable Jacket	Grey
Comments	Class E up to 250 MHz acc. to ISO/IEC 11801
Component Type	Cable Assembly
IP Rating	IP20
Length	10.0m
Material - Outer Jacket	LSZH
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Patch Cords
Product Name	GWconnect
Standard	EIA-TIA - 568-C.2, EN 50173-2, IEC 60332.1
Type	RJ45 CAT6
UPC	887191835457

Physical

Gender	Plug/Plug
Lock to Mating Part	Yes
Material - Plating	Gold
Net Weight	397.000/g
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	8p/8C
Temperature Range - Operating	0° to +75°C
Wire Size AWG	26

Material Info

Engineering Number	2100.3406.A
--------------------	-------------

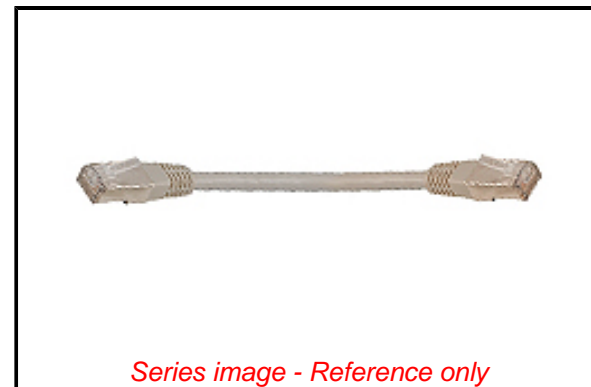

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Not Relevant

Compliant

Not Contained

Search Parts in this Series

[93606 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93606-0089](#)