

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936358314](#)

Status: **Active**

Overview: [Magnetic Jacks](#)

Description: MXMag Fast Ethernet 6 Core Non-PoE Single-Port RJ45 Connector, 21.40mm Depth, 3.30mm Phy Pin Length, Right-Angle, Inverted Profile, with Shield Tabs, with Yellow-Green LEDs, Industrial Temperature, Tray

Documents:

[3D Model](#)

[Drawing \(PDF\)](#)

[3D Model \(PDF\)](#)

[Product Specification 934620001-K \(PDF\)](#)

[Packaging Specification 934620001-K \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Modular Jacks/Plugs
Series	93635
Component Type	PCB Jack
Depth	21.40mm
Magnetic	Yes
Overview	Magnetic Jacks
Performance Category	100Mb
Power over Ethernet (PoE)	Non-PoE
Product Name	Magnetic Jack, MXMag, RJ45
UPC	889056572460

Physical

Color - Resin	Black
Durability (mating cycles max)	2500
Inverted / Top Latch	Yes
Jack Height	14.10mm
Keying to Mating Part	None
Lightpipes/LEDs	LEDs
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold over Palladium Nickel
Material - Plating Termination	Tin
Material - Resin	Liquid Crystal Polymer
Net Weight	6.285/g
Orientation	Right Angle (Side Entry)
PCB Locator	Yes
PCB Retention	None
PCB Thickness - Recommended	1.57mm
Packaging Type	Tray
Panel Mount	Spring Tabs
Plating min - Mating	0.051µm (Au), 1.016µm (PdNi)
Port Configuration	1x1
Positions / Loaded Contacts	8/8
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40° to +85°C
Termination Interface: Style	Through Hole
Wire/Cable Type	N/A

Electrical

Current - Maximum per Contact	0.5A
Grounding to PCB	Yes
Grounding to Panel	Yes
Shielded	Yes
Voltage - Maximum	125V

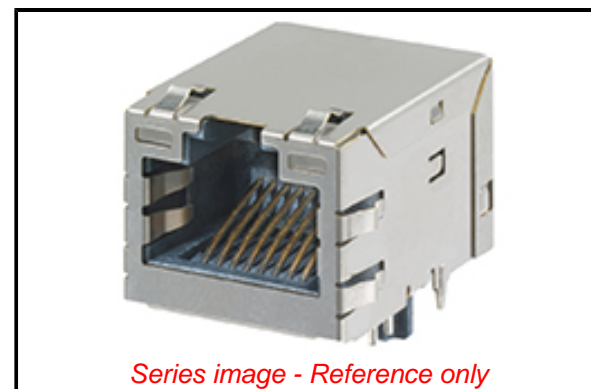

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 7(c)-I

REACH SVHC

Not Contained Per - D(2021)4569-DC (8 July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

50 Image

Not Relevant

Not Contained

Search Parts in this Series

[93635 Series](#)

Mates With

IEC 60603 / TIA-1096-A

Material Info

Reference - Drawing Numbers

Packaging Specification

934620001-K

Product Specification

934620001-K

Sales Drawing

934620003-K, 936350001-000

This document was generated on 09/14/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93635-8314](#)