

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0982660400**

Status: **Active**

Overview: FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description: 0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 254.00mm Cable Length, Tin (Sn) Plating, 36 Circuits

Documents:

[Drawing \(PDF\)](#)

[Product Specification PS-98266-001-001 \(PDF\)](#)

[Packaging Specification PK-98266-001-001 \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable
Series	98266
Comments	Contacts on opposite sides, Type D
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
UPC	756054768570

Physical

Cable Length	254.00mm
Circuits (Loaded)	36
Contact Layout Type	D (opposite side)
Material - Plating Mating	Tin
Net Weight	2.928/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable


Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-98266-001-001
Product Specification	PS-98266-001-001
Sales Drawing	SD-98266-001

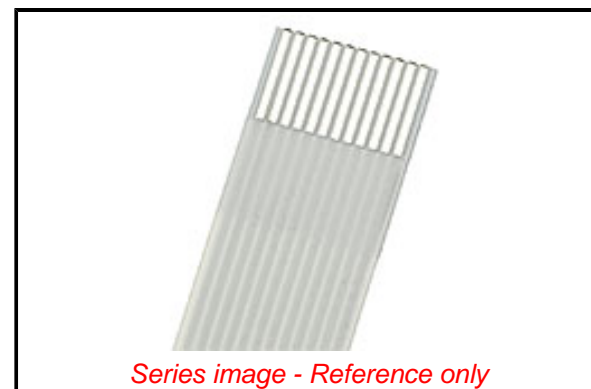

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

China RoHS

Search Parts in this Series

98266 Series

Mates With

Easy-On FFC/FPC Connector:

541043633 , 541323633 , 525593633

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[98266-0400](#)