

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0982680868

Status:


Active

Overview:

FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description:

1.25mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 203.00mm Cable Length, Tin (Sn) Plating, 17 Circuits

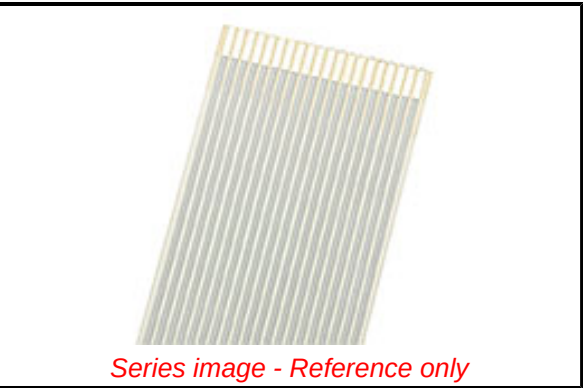

Documents:

Drawing (PDF)

Product Specification PS-98268-001-001 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

|                               |                                                           |
|-------------------------------|-----------------------------------------------------------|
| General                       |                                                           |
| Product Family                | Cable                                                     |
| Series                        | 98268                                                     |
| Comments                      | Contacts on opposite sides, Type D                        |
| Crimp Quality Equipment       | Yes                                                       |
| Overview                      | FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers |
| Product Name                  | Premo-Flex FFC Jumper                                     |
| UPC                           | 800756946245                                              |
| Physical                      |                                                           |
| Cable Length                  | 203.00mm                                                  |
| Circuits (Loaded)             | 17                                                        |
| Contact Layout Type           | D (opposite side)                                         |
| Material - Plating Mating     | Tin                                                       |
| Packaging Type                | Bag                                                       |
| Pitch - Mating Interface      | 1.25mm                                                    |
| Temperature Range - Operating | -40° to +105°C                                            |
| Wire Size AWG                 | N/A                                                       |
| Wire/Cable Type               | Flat Flex Cable                                           |
| Electrical                    |                                                           |
| Current - Maximum per Contact | 1.4A                                                      |
| Voltage - Maximum             | 60V AC                                                    |
| Material Info                 |                                                           |
| Reference - Drawing Numbers   |                                                           |
| Product Specification         | PS-98268-001-001                                          |
| Sales Drawing                 | SD-98268-001-001                                          |

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

98268 Series

Mates With

<a href="http://www.molex.com/product/ffc">Molex FFC – FPC connector</a>. Be sure to match like plating.

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[98268-0868](#)