

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0984381004](#)
Status: **Active**
Description: 5.00mm Pitch NSCC/SICMA Female Wire-to-Board Housing, for 2.80mm Tab, with Bridges, Dual Row, 6 Circuits, Blue

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Application Specification AS-98438-001-001 \(PDF\)](#)

General

Product Family	Crimp Housings
Series	98438
Application	Power, Wire-to-Board
Comments	For current designation please refer to FCI Sicma terminal specification for 2.80mm terminals.
Product Name	NSCC
UPC	822350104333

Physical

Circuits (maximum)	6
Color - Resin	Black, Natural
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	5.162/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	5.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C


Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Reference - Drawing Numbers

Application Specification	AS-98438-001-001
Sales Drawing	SD-98438-001

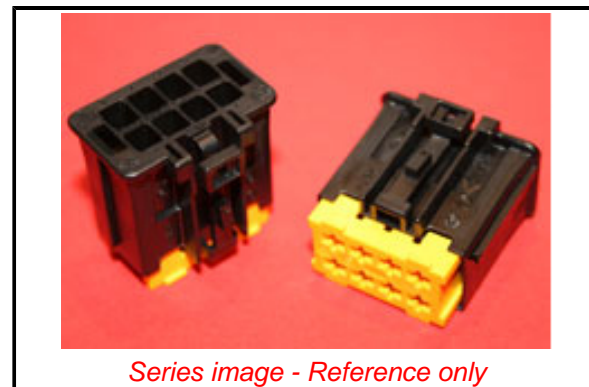

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/71/2019 (16 July 2019)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series

[98438](#) Series

Mates With

[98898](#) UCC2 Terminals

Use With

[98898](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[98438-1004](#) [98438-1002](#)