

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0988231011](#)
Status: **Active**
Overview: NSCC - New Standard Casing Contact
Description: NSCC Male Housing, Terminal Size 1.50mm, Non-Sealed, 5.0mm Pitch, 10 Circuits, Black

Documents:

[3D Model](#) [Packaging Specification PK-31301-635-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Application Specification AS-98816-001-001 \(PDF\)](#)

General

Product Family Crimp Housings
Series [98823](#)
Application Power, Wire-to-Wire
Comments Pitch Center Spacing: Horizontal Pitch 3.33mm, Vertical pitch 6.00mm
Overview [NSCC - New Standard Casing Contact](#)
Product Name NSCC
UPC 822348761432

Physical

Circuits (maximum) 10
Circuits Detail 10x1.5mm pins
Color - Resin Black
Gender Plug
Glow-Wire Capable No
Keying to Mating Part Yes
Lock to Mating Part Yes
Material - Resin Polyester
Net Weight 7.900/g
Number of Rows 2
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 3.33mm, 6.00mm
Polarized to Mating Part Yes
Ports 1
Temperature Range - Operating -40° to +100°C

Electrical

Current - Maximum per Contact 10.0A

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number 08111EV10F1

Reference - Drawing Numbers

Application Specification AS-98816-001-001
Packaging Specification PK-31301-635-001
Sales Drawing SD-98823-001

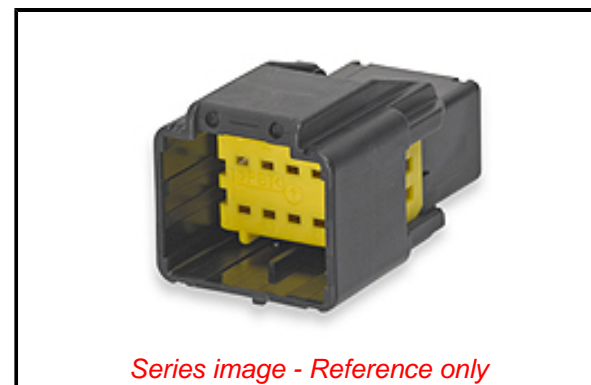

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)4578-DC (25
June 2020)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[98823](#) Series

Mates With

[988161011](#) , [988161111](#) (Female Receptacle Housing)

Use With

Use: Male FCI Terminals

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[98823-1011](#)