

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1062840005](#)
Status: **Active**
Overview: Optical Connectivity Solutions
Description: CXP Optical Cable Assembly (iPass+), MTP-to-MTP, Multimode, 50/125µm, Round Cable Assembly, Straight Boot, Standard Bandwidth, OFNR, Cable Diameter 3.80mm, Cable Length 5.00m

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

| | |
|------------------------|---------------------------------------|
| Product Family | Fiber Optic Assemblies |
| Series | 106284 |
| Boot Type | Straight |
| Connector to Connector | MTP-to-MTP |
| Mode | Multimode |
| Overview | <u>Optical Connectivity Solutions</u> |
| Product Name | CXP, iPass+, MTP |
| UPC | 883906549985 |

Physical

| | |
|-----------------------|--------------------|
| Cable Length | 5.0m |
| Cable Size | 3.80mm |
| Fiber (Core/Cladding) | 50/125µm |
| Net Weight | 96.300/g |
| Single Ended | No |
| Wire/Cable Type | Fiber Optic, Round |


Solder Process Data

| | |
|-----------------------------|-----|
| Lead-freeProcess Capability | N/A |
|-----------------------------|-----|

Material Info

Reference - Drawing Numbers

| | |
|---------------|--------------------|
| Sales Drawing | SD-106284-0001-001 |
|---------------|--------------------|

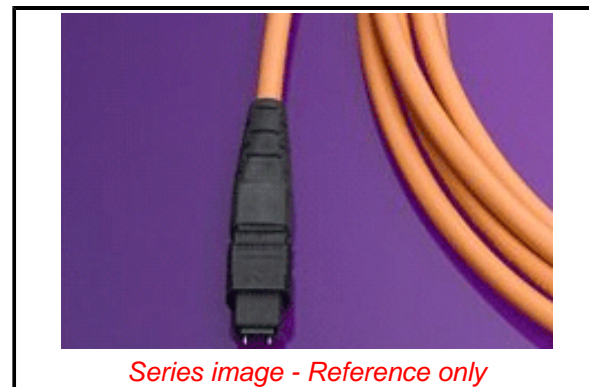

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2020)9139-DC (19 Jan 2021)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

50 Image

Not Relevant

Not Contained

Search Parts in this Series

[106284 Series](#)

Mates With

CXP Optical Transceivers

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[106284-0005](#)