

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1062840010](#)  
**Status:** **Active**  
**Overview:** Optical Connectivity Solutions  
**Description:** CXP Optical Cable Assembly (iPass+ ), MTP-to-MTP, Multimode, 50/125µm, Round Cable Assembly, Straight Boot, Standard Bandwidth, OFNR, Cable Diameter 3.80mm, Cable Length 10.00m

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Fiber Optic Assemblies
Series	<a href="#">106284</a>
Boot Type	Straight
Connector to Connector	MTP-to-MTP
Mode	Multimode
Overview	<u>Optical Connectivity Solutions</u>
Product Name	CXP, iPass+, MTP
UPC	883906549992

**Physical**

Cable Length	10.0m
Cable Size	3.80mm
Fiber (Core/Cladding)	50/125µm
Net Weight	175.194/g
Single Ended	No
Wire/Cable Type	Fiber Optic, Round


**Solder Process Data**

Lead-freeProcess Capability	N/A
-----------------------------	-----

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing	SD-106284-0001-001
---------------	--------------------

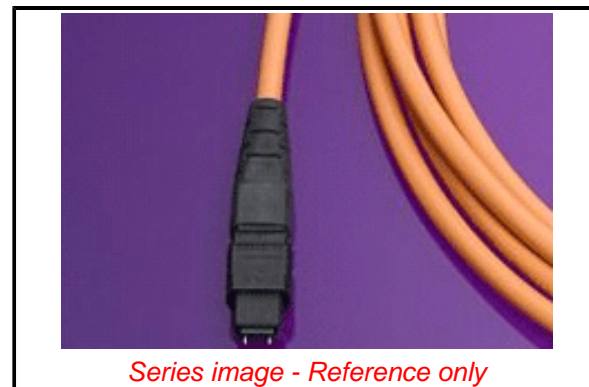

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Contained Per -  
D(2021)4569-DC (8  
July 2021)

Lead

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

50 Image

Not Relevant

Not Contained

**Search Parts in this Series**

[106284](#) Series

**Mates With**

CXP Optical Transceivers

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[106284-0010](#)