

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1062841002](#)
Status: **Active**
Overview: [Optical Connectivity Solutions](#)
Description: CXP Optical Cable Assembly (iPass+), MTP-to-MTP, Multimode, 50/125µm, Round Cable Assembly, Straight Boot, High Bandwidth, OFNR, Cable Diameter 4.50mm, Cable Length 2.00m

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Fiber Optic Assemblies
Series	106284
Boot Type	Straight
Connector to Connector	MTP-to-MTP
Mode	Multimode
Overview	Optical Connectivity Solutions
Product Name	CXP, iPass+, MTP
UPC	884982912373

Physical

Cable Length	2.0m
Cable Size	3.80mm
Fiber (Core/Cladding)	50/125µm
Net Weight	49.790/g
Single Ended	No
Wire/Cable Type	Fiber Optic, Round


Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-106284-0001-001
---------------	--------------------

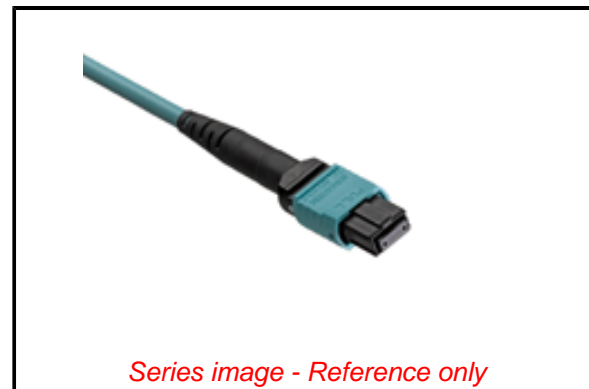

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2020)9139-DC (19 Jan 2021)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

50 Image

Not Relevant

Not Contained

Search Parts in this Series

[106284 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[106284-1002](#)