

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1110683200](#)  
**Status:** **Active**  
**Overview:** [iPass+ HD Interconnect System](#)  
**Description:** [iPass X4 Mini SAS HD-to-Mini SAS 2.0, 0.50m, 30 AWG](#)

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Application Specification 1110750001-000 \(PDF\)](#)

**General**

Product Family	Cable Assemblies
Series	<a href="#">111068</a>
Assembly Configuration	Dual Ended Connectors
Connector to Connector	iPass HD-to-Mini SAS
Overview	<a href="#">iPass+ HD Interconnect System</a>
Product Name	iPass, X4
UPC	884982770690

**Physical**

Cable Length	0.50m
Circuits (Loaded)	36
Gender	Male-Male
Lock to Mating Part	Yes
Material - Metal	Zinc Alloy
Material - Plating Mating	Gold
Net Weight	102.000/g
Single Ended	No
Waterproof / Dustproof	No
Wire Insulation Diameter	N/A
Wire Size AWG	30
Wire/Cable Type	Parallel Pair


**Electrical**

Impedance	100Ω
Shielded	Yes

**Material Info**

**Reference - Drawing Numbers**

Application Specification	1110750001-000
Sales Drawing	SD-111068-3200

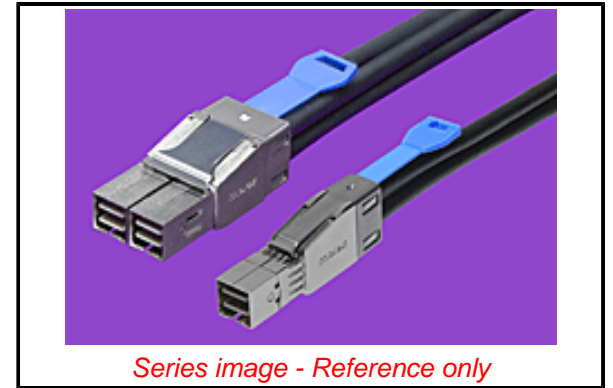

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
 -ED/01/2018 (15  
 January 2018)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[111068 Series](#)

**Mates With**

HD Plug Mates to 1x1, 1x2 and x4  
 Receptacle - EMI Housing [46866](#). Mini-SAS  
 Plug mates to Receptacle [755860004](#) and  
 EMI Housing [4548>BR>](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[111068-3200](#)