

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1120115034](#)
Status: **Active**
Overview: [PC Network Interface Cards](#)
Description: PCU-DP2IO PROFIBUS-DP Master/Slave 12 Mbps, PCI Universal bus - Bulk of 25


Documents:

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Network Interface
Series	112011
Application	IO Control
Approvals	CE certified
Overview	PC Network Interface Cards
Product Name	applicom IO
Protocol	PROFIBUS
Protocol Detail	PROFIBUS DPV0 Master, PROFIBUS DPV0 Slave, PROFIBUS DPV1 Master
Software Downloads	DRL-DPM-PCU
Type	PROFIBUS Card
UPC	887191523682
Physical	
Channels	1
Communication Speed	PROFIBUS 9.6 kbps to 12 Mbps
Interface	DLL, OPC DA
Mounting Style	PC Slot
Net Weight	121.000/g
Network Connection Type	PROFIBUS D-Sub Female (9 pin)
Operating System	Windows7, Windows8/8.1, Windows Server 2003, Windows Server 2008, Windows Server 2012, Windows Vista, WindowsXP
Packaging Type	Carton
Processor	PowerPC 8323
Slot	Universal PCI 3.3V/5V
Temperature Range - Operating	0°C to +60°C
Electrical	
Current - Maximum Input	5.5W
EMC	EN 55022 Class B, EN 61000-3-2, EN 61000-3-3, IEC 61000-6-2
Supply Voltage	3.3/5V
Material Info	
Engineering Number	DR2-DPM-PCU-B25

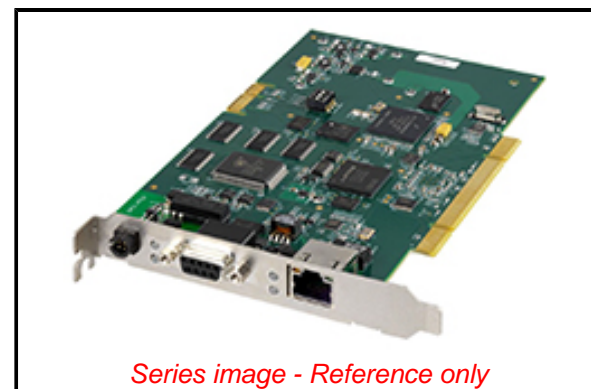

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 7(c)-I,6(c),7(a)

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[112011 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1120115034](#)