

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1120361001](#)  
**Status:** **Active**  
**Overview:** [Industrial Ethernet Switches](#)  
**Description:** IP20 Unmanaged Ethernet Switch, 8 Ports, 10/100Mb Data Speed

**Documents:**

[Datasheet \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Switches
Series	<a href="#">112036</a>
Approvals	CE, FCC, UL (pending)
Comments	10/100 Base TX (Mbaud)
Data Speed	Fast Ethernet (10/100Mbps)
IP Rating	IP20
MAC Address	8192
Overview	<a href="#">Industrial Ethernet Switches</a>
Product Name	IP20 Unmanaged Ethernet Switch
Protocol	N/A
Switch Functionality	Unmanaged
UPC	78172561265

**Physical**


Ethernet Connector	RJ45
Housing Depth	99.60mm
Housing Length	116.00mm
Housing Width	46.00mm
Mechanical Shock	IEC 60068-2-27
Mounting Style	DIN Rail, Wall
Packaging Type	Carton
Ports	8
Power Input	24V DC
Temperature Range - Operating	-40° to +70°C
Uplink Connection	N/A
Vibration	IEC 60068-2-6

**Electrical**

Current - Maximum Output	N/A
EMC	CE, EN 610006-2-4, FCC Part 15, ICES-003
Supply Voltage	24V DC

**Material Info**

Engineering Number	DRL-280MB
--------------------	-----------

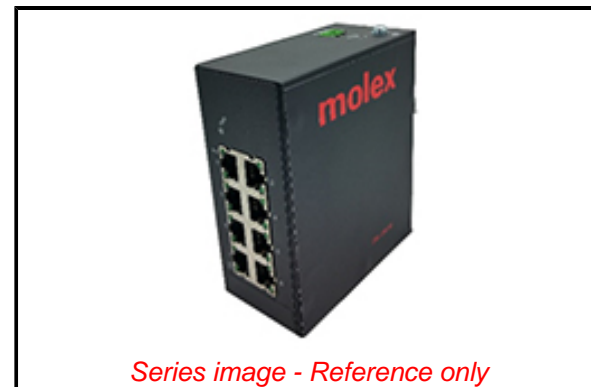

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[112036 Series](#)

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[112036-1001](#)