

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1120955137](#)  
**Status:** **Active**  
**Overview:** IP67-Rated HarshIO Modules  
**Description:** Brad HarshIO Digital Module for EtherNet/IP, Classic 60mm, IP67, 8 ports M12, 16 Inputs, PNP, 4 Pole Power, 3 Rotary Switch

**Documents:**

[3D Model](#) [3D Model \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

UL E200650

**General**

Product Family Industrial I/O Modules  
 Series [112095](#)  
 Application Filling and Packaging Machines, Machine Tool Industry, Material Handling Systems  
 Approvals ODVA, UL, cUL, CE  
 IP Rating IP67  
 Overview [IP67-Rated HarshIO Modules](#)  
 Product Name HarshIO EtherNet/IP  
 Protocol EtherNet/IP  
 Software Downloads TCDEI-8xxP-DxU-G02  
 UPC 889056361897

**Physical**

Bus Input 4-pole Ultra-Lock (M12), D-Coded, Female  
 Bus Output 4-pole Ultra-Lock (M12), D-Coded, Female  
 Format Classic (60mm)  
 Housing Width 60.00mm  
 I/O Connector 5-pole Ultra-Lock (M12), A-Coded, Female  
 I/O Ports 8x M12  
 I/O Signal Mix 16 input  
 Mechanical Shock 10G, 11ms, 3 AXIS  
 Power Input 4-pole Mini-Change, Male  
 Power Output 4-pole Mini-Change, Female  
 Temperature Range - Operating -25°C to +70°C  
 Vibration IEC 60068-2-6

**Electrical**


Current - Maximum Output 2.0A per Channel  
 EMC IEC 61000-6-2  
 Input Delay 5 ms  
 Input Device Supply 140 mA per port at 25°C  
 Input Type PNP or Dry Contact

**Material Info**

Engineering Number TCDEI-8D0P-DYU-G02

**Reference - Drawing Numbers**

Sales Drawing 1120955011-000

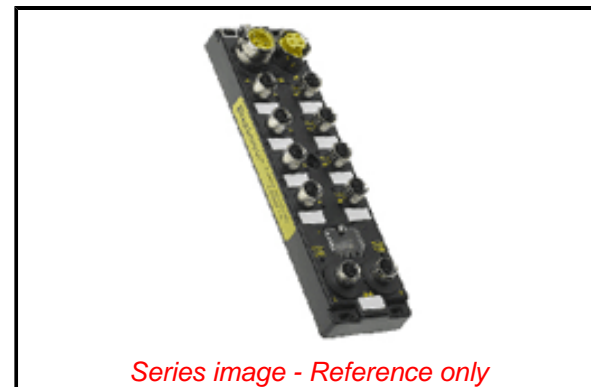

Series image - Reference only

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[112095 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[112095-5137](#)