

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200900062](#)
Status: **Active**
Overview: [Brad Nano-Change \(M8\) Products](#)
Description: Nano-Change (M8) Receptacle, 3 Poles, M8 x 0.5 Mounting Threads, Male (Straight) to Leads, 0.60m (1.97') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E46237

General

Product Family Industrial Receptacles
 Series [120090](#)
 IP Rating IP67
 NEMA Rating NEMA 6
 Overview [Brad Nano-Change \(M8\) Products](#)
 Product Name Nano-Change (M8)
 Type Single Ended (pigtail)
 UPC 78678897268

Physical

Coupling Type External Thread
 Gender Male
 Keyway None
 Length 0.60m
 Material - Component Nickel-plated Brass
 Mounting Thread Size M8 x 0.5
 Orientation Straight
 Panel Mount Front
 Poles 3
 Temperature Range - Operating -20° to +105°C
 Wire Size AWG 24
 Wire/Cable Type N/A

Electrical


Current - Maximum per Contact 4.0A
 Voltage - Maximum 60V AC / 75V DC

Material Info

Engineering Number 4R3P06A27C600

Reference - Drawing Numbers

Sales Drawing SD-120090-020-001

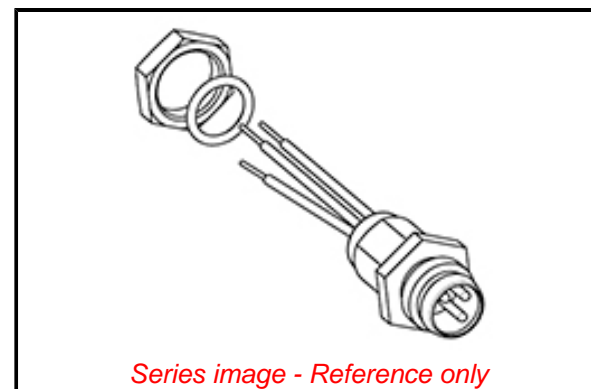

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c),7(c)-I

REACH SVHC

Contained Per - ED/01/2018 (15 January 2018)
 2,4-Di-tert-butyl-6-(5-chlorobenzotriazol-2-yl)p

Bisphenol-A

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[120090 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1200900062](#)