

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200980203](#)
Status: **Active**
Overview: PROFIBUS Solutions
Description: PROFIBUS 90° Female/Male D-Sub Connector to Pigtail, With Programming Port, 22 AWG, PUR Cable, 1.0m (3.28') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	120098
Comments	With Programming Port
Connector End A	D-Sub (9-pin)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	N/A
Overview	PROFIBUS Solutions
Product Name	PROFIBUS
Protocol	N/A
Region	America, Asia, Europe
Type	Single Ended
UPC	78172504509

Physical

Cable Diameter	8.00mm (.315")
Cable Length	1.0m (3.28')
Color - Cable Jacket	Purple
Coupling Style	Threaded
Gender	Female/Male to Pigtail
Keyway	None
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR
Material - Coupling Nut	Gray Anodized Aluminum
Material - Plating Mating	N/A
Orientation	90°/90° to Pigtail
Poles	N/A
Temperature Range - Operating	0° to +60°C
Wire Size AWG	N/A
Wire/Cable Type	Shielded-Twisted Pair

Electrical


Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC

Material Info

Engineering Number	P03S07PP4M010
--------------------	---------------

Reference - Drawing Numbers

Sales Drawing	SD-120098-029-001
---------------	-------------------

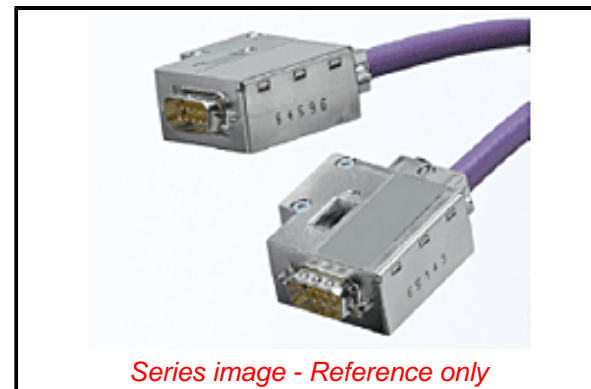

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

China RoHS

Search Parts in this Series

[120098 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1200980203](#)