

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1201030001](#)
Status: **Active**
Overview: PROFIBUS Solutions
Description: PROFIBUS Attachable D-Sub Connector with Diagnostics LEDs and Programming Port, 90° Angle

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Field Attachable / Accessories
Series	120103
IP Rating	IP67
Material - Contact	N/A
Overview	PROFIBUS Solutions
Product Name	D-Sub, PROFIBUS
Type	Field Attachable Connector
UPC	78678853530

Physical

Cable Diameter	N/A
Coupling Type	N/A
Diagnostics / LEDs	Yes
Diagnostics Port	Yes
Gender	N/A
Keyway	None
Material - Connector Body	Die-Cast Zinc
Material - Coupling Nut	N/A
Material - Plating Mating	n/a
Net Weight	90.000/g
Orientation	90° Angle
Poles	N/A
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	N/A

Electrical


Current - Maximum per Contact	4.0A
Voltage - Maximum	30V

Material Info

Engineering Number	PA9D01-42
--------------------	-----------

Reference - Drawing Numbers

Sales Drawing	SD-120103-003-001
---------------	-------------------

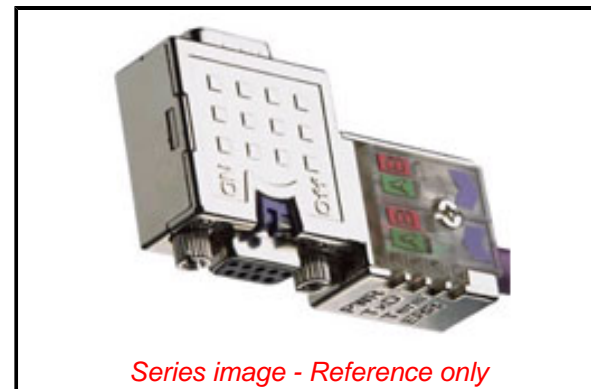

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_CE -

Declaration of

Conformity

China RoHS

Green Image

Not Relevant

Not Contained

CER_4000380995_00_000.pdf

Search Parts in this Series

[120103 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1201030001](#) [PA9D01-42](#)