

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1202320023](#)
Status: **Active**
Overview: Brad M23 Signal and Power Connectors
Description: Brad M23 Signal Connector, Female Insert, Solder Contacts, 12 Poles

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Field Attachable / Accessories
Series	120232
Application	Signal
Comments	Insert with Solder Contacts
IP Rating	IP67
Material - Contact	N/A
Overview	Brad M23 Signal and Power Connectors
Product Name	Brad M23
Type	Field Attachable Connector
UPC	883906205300

Physical

Cable Diameter	N/A
Coupling Type	N/A
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Female
Keyway	None
Material - Connector Body	Nylon
Material - Coupling Nut	N/A
Material - Plating Mating	n/a
Net Weight	8.560/g
Orientation	Straight
Poles	12
Temperature Range - Operating	-40°C to +125°C
Wire Size AWG	N/A

Electrical


Current - Maximum per Contact	N/A
Voltage - Maximum	N/A

Material Info

Engineering Number	KISC0-55
--------------------	----------

Reference - Drawing Numbers

Sales Drawing	SD-120232-023-001
---------------	-------------------

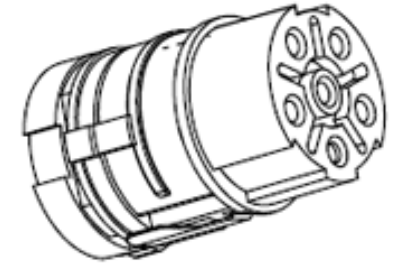

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)

Lead

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_CE -

Declaration of

Conformity

China RoHS

50 Image

Not Relevant

Not Contained

CER_4000381005_00_000.pdf

Search Parts in this Series

[120232 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1202320023](#)